


**Model: L63502432-0, L63504040-0**

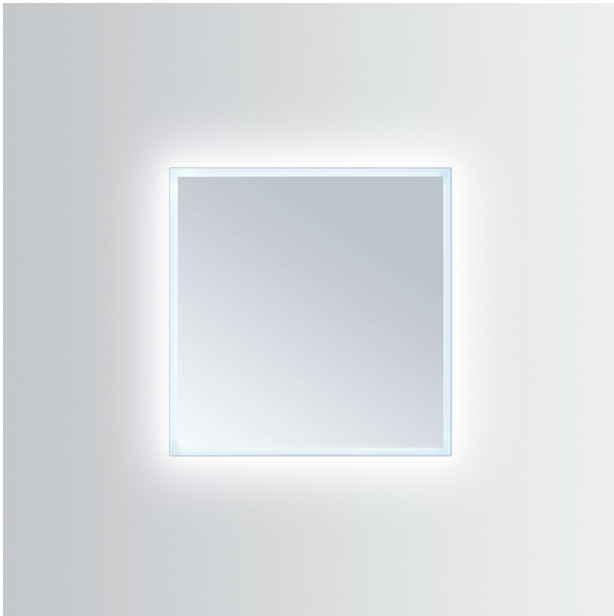

### FEATURES

- Energy Efficient and Long Lasting LED Lighting
- Acrylic Light Diffuser
- Durable Aluminum Frame with Steel Back Panel

### LIGHTING


- LED (Light-Emitting Diode)
- Average Bulb Life of 50,000 hours
- Color Temperature: 6000K (Daylight)
- Brightness: see page 2
- Power Consumption: see page 2

### SAFETY

- Safety Backed Mirror
- IP44 Rated

### OVERVIEW

Innoci-usa does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. Innoci-usa prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

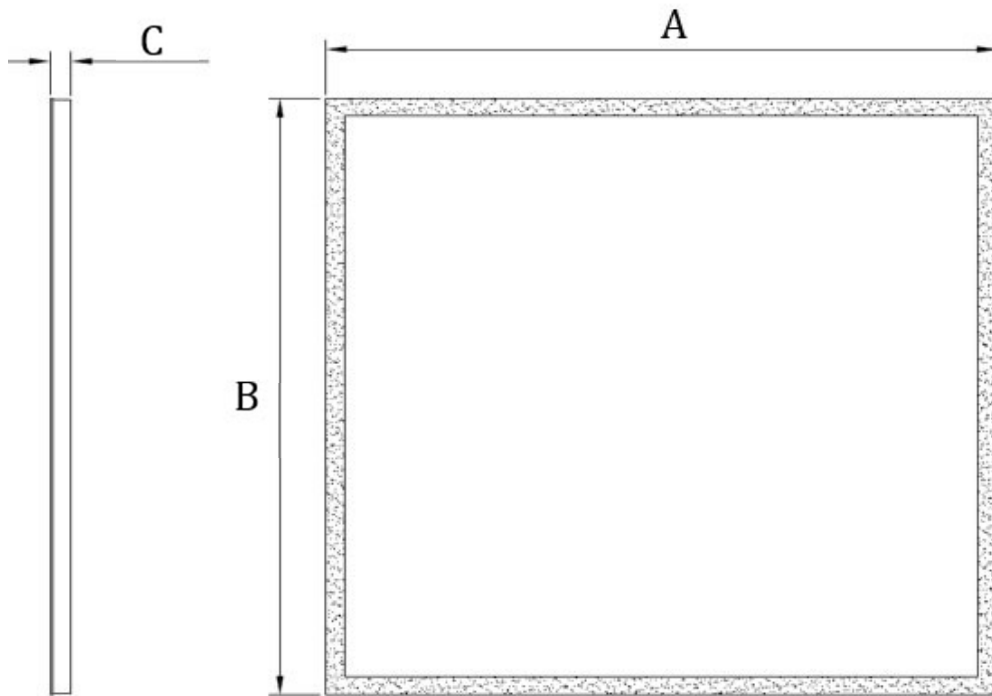

Model #	A	B	C	Brightness (Lumen)	Power Consumption (Watt)
L63502432-0	24	32	1 1/4	1530	25
L63504040-0	40	40	1 1/4	2250	36

Innoci-USA INC  
Newport Beach, CA 92660

[www.innoci-usa.com](http://www.innoci-usa.com)  
(866) 479-8076

[customerservice@innoci-usa.com](mailto:customerservice@innoci-usa.com)

**innociusa**  
LIFESTYLE

Rev. 8.5.1