

Model: L66116035



FEATURES

- Energy Efficient and Long-Lasting LED Lighting
- Built-in Rocker Switch for Added Convenience
- 5mm Copper-free Mirror
- Durable Aluminum Frame with Steel Back Panel
- Surface-Mount with French Cleat Mounting Bracket
- Can be Hung in Portrait or Landscape
- Hardwired (Junction box required)

LIGHTING

- Front-Facing Lighting
- Average Bulb Life of 50,000 hours
- CRI: 85+
- Color Temperature: 6000K (Daylight)
- Brightness: see page 2
- Power Consumption: see page 2


SAFETY

- Safety Backed Mirror
- IP44 Rated
- UL certified

*** Not compatible with wall dimmer switch.**

OVERVIEW

innoci-usa does not cut corners and only uses the highest quality components and bulbs to make sure that the mirror will be maintenance free and function like the day you purchased for average 50,000 hours of use. **innoci-usa** prides itself on providing unmatched price vs quality for all of our products. All mirrors come with a 5-year limited warranty.

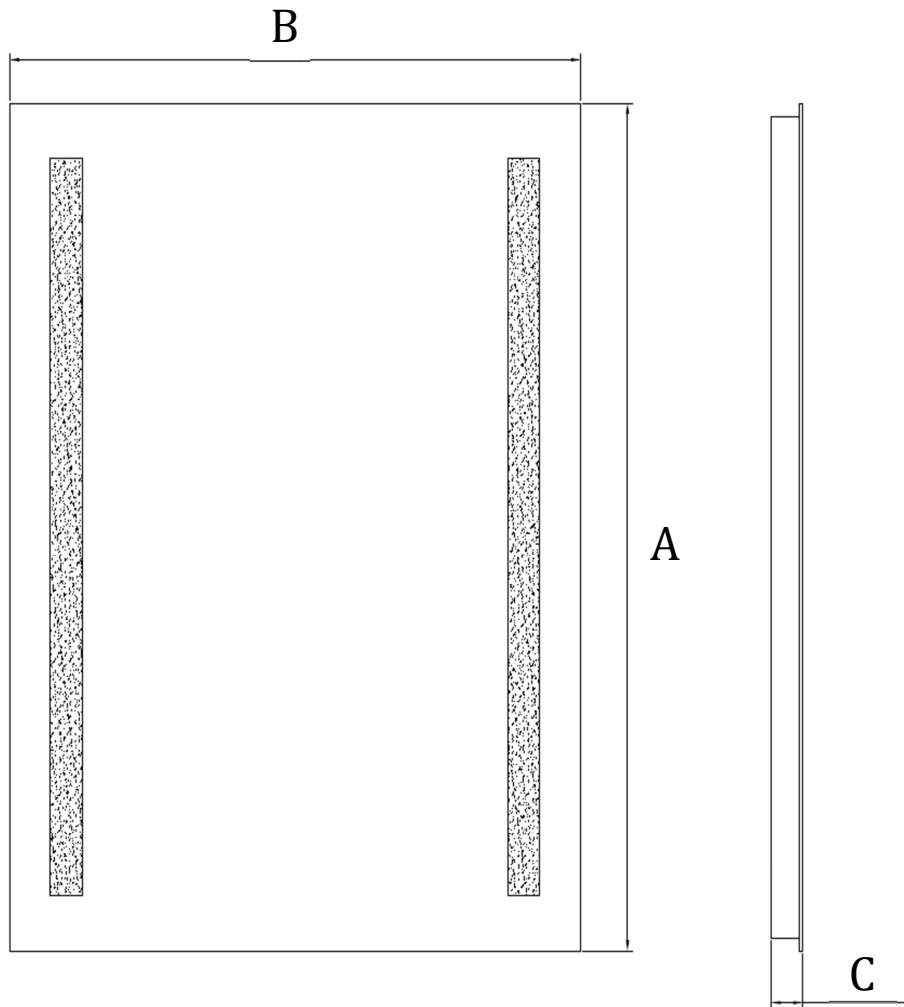

Model #	A	B	C	Brightness (Lumen)	Power Consumption (Watt)
L66116035	60	35	1 5/8	5880	47.1

Innoci-USA INC
Newport Beach, CA 92660

www.innoci-usa.com
(866) 479-8076

customerservice@innoci-usa.com

innociusa
LIFESTYLE