

# DEWALT®

## 20V MAX\*/LITHIUM ION

### PERFORMANCE

UP TO  
**57%**  
FASTER†

UP TO  
**35%**  
MORE RUNTIME  
Per Charge†

### ERGONOMICS



UP TO  
**38%**  
LIGHTER WEIGHT†

**OPTIMIZED HANDLE DESIGN**  
Contoured with slim profile


**IDEAL BALANCE**

†Speed and runtime claims are versus other leading 18 volt lithium ion tools. Weight claim is versus DC9096.

### INNOVATIVE FEATURES



**ONE-HANDED LOADING  
1/4" HEX CHUCK**

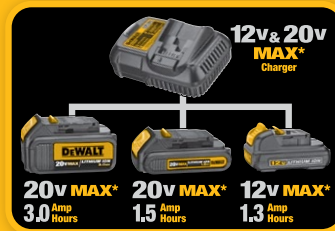

**DUAL VOLTAGE  
12V MAX\* & 20V MAX\* CHARGER**



**3-LED ILLUMINATION WITH DELAY**



**3-SPEED TRANSMISSION  
ON PREMIUM DRILLS**

## 20V MAX\* POWER. MAXIMUM PERFORMANCE.



With up to 57% faster application speed and up to 35% more runtime than leading 18 Volt lithium ion tools, there's no stopping the 20V MAX\* system. The speed, power and control are up to almost any job. Available 3.0 Amp Hour (Ah) and 1.5 Ah lithium ion batteries make it a versatile system. And the comfortable design lets you work all day and get more done.

## 20V MAX\*/LITHIUM ION

**DEWALT**  
www.dewalt.com

\* With respect to the 12V MAX\*: Maximum initial battery voltage (measured without a workload) is 12 volts. Nominal voltage is 10.8. With respect to the 20V MAX\*: Maximum initial battery voltage (measured without a workload) is 20 volts. Nominal voltage is 18. †Speed and runtime claims are versus leading 18 volt lithium ion tools. Copyright © 2012 DeWALT. The following are examples of trademarks for one or more DeWALT power tools and accessories: The yellow and black color scheme; the "D" shaped air intake grill; the array of pyramids on the handgrip; the kit box configuration; and the array of lozenge-shaped humps on the surface of the tool.

# 20V MAX\* DRILLS



**DCD985L2 11A178**  
Premium 3-Speed Hammerdrill Kit  
(3.0 Ah)



**DCD980L2 11A177**  
Premium 3-Speed Drill/Driver Kit  
(3.0 Ah)



**DCD785C2 11A172**  
Compact Hammerdrill/Driver Kit (1.5 Ah)



**DCD780C2 11A170**  
Compact Drill/Driver Kit (1.5 Ah)



**DC740C1 11A173**  
3/8" Right Angle Drill Kit (1.5 Ah)



**DCH213L2 11A160**  
3-Mode SDS Rotary Hammer Kit  
(3.0 Ah)

# 20V MAX\* IMPACTS



**DCF885C2 11A180**  
1/4" Impact Driver Kit (1.5 Ah)



**DCF885L2 11A181**  
1/4" Impact Driver Kit (3.0 Ah)

# 20V MAX\* SAWS



**DCS380L1 11A179**  
Reciprocating Saw Kit (3.0 Ah)



**DCS391L1 11A166**  
6-1/2" Circular Saw Kit (3.0 Ah)

# 20V MAX\* LIGHTS



**DCL040 11A159**  
LED Flashlight

# 20V MAX\* COMBO KITS



**DCK280C2 11A169**  
20V MAX\* Compact Drill/Driver /  
Impact Driver Combo Kit (1.5 Ah)



**DCK285C2 11A171**  
20V MAX\* Compact Hammerdrill /  
Impact Driver Combo Kit (1.5 Ah)



**DCK290L2 11A174**  
20V MAX\* Hammerdrill /  
Impact Driver Combo Kit (3.0 Ah)



**DCK292L2 11A175**  
20V MAX\* Hammerdrill /  
Recip Saw Combo Kit (3.0 Ah)



**DCK294L3 11A176**  
20V MAX\* Hammerdrill (3.0 Ah) /  
12V MAX\* Screwdriver Combo Kit



**DCK490L2 11A162**  
20V MAX\* 4-Tool Combo Kit (3.0 Ah)



**DCK491L2 11A161**  
20V MAX\* 4-Tool Combo Kit (3.0 Ah)



**DCK590L2 11A163**  
20V MAX\* 5-Tool Combo Kit (3.0 Ah)

# BATTERIES & CHARGERS



**DCB200 11A165**  
20V MAX\* 3.0 Ah Battery Pack



**DCB200-2 11A164**  
20V MAX\* 3.0 Ah Battery 2-Pack



**DCB201 11A168**  
20V MAX\* 1.5 Ah Battery Pack



**DCB201-2 11A167**  
20V MAX\* 1.5 Ah Battery 2-Pack (1.5 Ah)



**DCB101 11A157**  
12V MAX\* - 20V MAX\* Battery Charger



**DCB119 11A158**  
12V MAX\* - 20V MAX\*  
Vehicle Battery Charger

**20V MAX\* / LITHIUM ION**

**COMING SOON...**



AVAILABLE THROUGH  
**GRAINGER**  
FOR THE ONES WHO GET IT DONE

8SS4643 DWGR20VMAXSS