

formerly AOSafety™ products now from 3M



3MTM MaximTM Protective Eyewear

The Maxim family of eyewear products offers prescription quality optics*, a dual-injected molded and lightweight frame, a high style design, and a full list of performance and adjustment features. Maxim eyewear featured in this brochure meet ANSI Z87.1-2003 and CSA Z94.3-2007.

*Maxim eyewear meets the optical requirements of ANSI Z80.1-2003, American National Standard for Ophthalmics



3M™ Maxim™ GT

Maxim GT brings sophistication, style and comfort to protective eyewear. Features include a lightweight frame with an elastomeric browguard for added comfort, and a high-wrap lens for better coverage and good optical clarity. The dual-injected adjustable temples with 3-position lens adjustment helps wearers get the best possible fit for day-long comfort.



Silver/Black



Task-specific

When first introduced, Maxim set the standard with the safety industry's first dual-aspheric plano lens, a dual-injected molded frame, an ultra high-style design, and a substantial list of performance and custom-adjust features.

How do you improve upon excellence? Maxim and Maxim Sport are available with an extended range of interchangeable lenses – five in all – to meet more needs for more wearers and more applications. The lenses can be easily changed for wearer preference or application and absorb 99.9% UV.



3M™ Maxim™ Sport

Maxim Sport has a dual-color frame design. It also features Sport Grip dual-injected temples and soft, elastomeric browguard. The lenses are interchangeable and have DX™ anti-fog hard coat to resist fog, scratching, and many chemicals.



Silver/Blue

3M™ Maxim™


Maxim features contemporary styling and a lightweight design, adjustable temple lengths and angles, dual-injected cushion browguard, and soft, adjustable nose bridge. The Maxim also offers a ventilation channel designed to help prevent fogging and vent heat away from the face.



Black



Denim

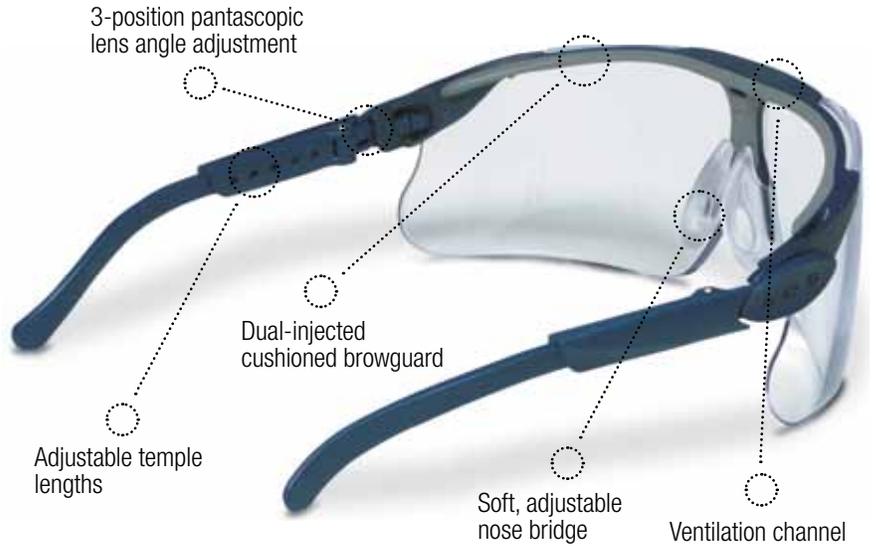

3-position pantoscopic lens angle adjustment

Dual-injected cushioned browguard

Adjustable temple lengths

Soft, adjustable nose bridge

Ventilation channel

lens options:



MinimzeR™



Gray




Clear



Bronze



I/O Mirror

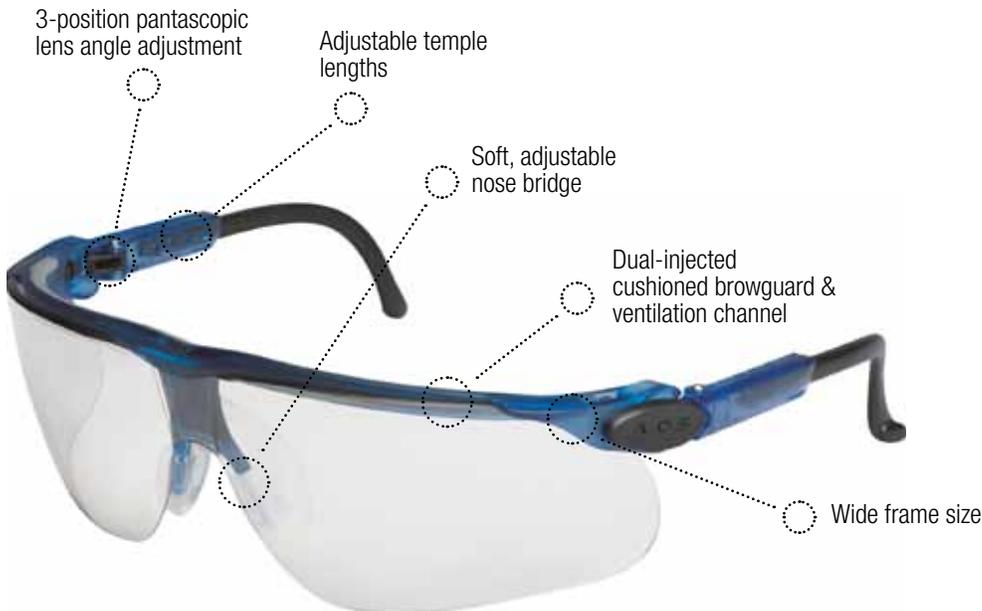

3-position pantoscopic lens angle adjustment

Adjustable temple lengths

Soft, adjustable nose bridge

Dual-injected cushioned browguard & ventilation channel

Wide frame size

3M™ Maxim™ Plus

Maxim Plus offers a wide frame size to fit workers with larger size heads. It also features adjustable temple lengths and angles, dual-injected cushion browguard, and soft, adjustable nose bridge. Another comfort feature is the ventilation channel, which is designed to help prevent fogging and vent heat away from the face.



Blue

Product Number	UPC	Stock Number	Product Name / Description	Quantity
MAXIM GT				
14246-00000-20	10078371626126	70071561594	3M™ Maxim™ GT Protective Eyewear 14246-00000-20 Clear AF Lens, Silver/Black Frame	20 ea/case
14247-00000-20	10078371626133	70071561602	3M™ Maxim™ GT Protective Eyewear 14247-00000-20, Gray AF Lens, Silver/Black Frame	20 ea/case
14248-00000-20	10078371626140	70071561610	3M™ Maxim™ GT Protective Eyewear 14248-00000-20 I/O Mirror Lens, Silver/Black Frame	20 ea/case
MAXIM PLUS				
12282-00000-20	10078371622296	70071541349	3M™ Maxim™ Plus Protective Eyewear 12282-00000-20 Clear AF Lens, Blue Frame	20 ea/case
12283-00000-20	10078371622302	70071541356	3M™ Maxim™ Plus Protective Eyewear 12283-00000-20 Gray AF Lens, Blue Frame	20 ea/case
12284-00000-20	10078371622319	70071541364	3M™ Maxim™ Plus Protective Eyewear 12284-00000-20 I/O AF Lens, Blue Frame	20 ea/case
MAXIM				
13250-00000-20	10078371622357	70071541406	3M™ Maxim™ Protective Eyewear 13250-00000-20 Clear Lens, Black Frame	20 ea/case
13251-00000-20	10078371622364	70071541414	3M™ Maxim™ Protective Eyewear 13251-00000-20 Bronze Lens, Black Frame	20 ea/case
13252-00000-20	10078371622371	70071541422	3M™ Maxim™ Protective Eyewear 13252-00000-20 I/O Mirror Lens, Black Frame	20 ea/case
12289-00000-20	10078371622326	70071541372	3M™ Maxim™ Protective Eyewear 12289-00000-20 MinimizeR™ Lens, Black Frame	20 ea/case
13259-00000-20	10078371622401	70071541455	3M™ Maxim™ Protective Eyewear 13259-00000-20 Clear Lens, Denim Frame	20 ea/case
MAXIM SPORT				
13274-10000-20	10078371622456	70071541505	3M™ Maxim™ Sport Protective Eyewear 13274-10000-20 Clear Lens, Silver/Blue Frame	20 ea/case
13280-10000-20	10078371622494	70071541547	3M™ Maxim™ Sport Protective Eyewear 13280-10000-20 I/O Mirror Lens, Silver/Blue Frame	20 ea/case
REPLACEMENT LENSES				
13267-00000-20	10078371622418	70071541463	3M™ Maxim™ Protective Eyewear 13267-10000-20 Clear Replacement Lens	20 ea/case
12295-00000-20	10078371622340	70071541398	3M™ Maxim™ Protective Eyewear 12295-10000-20 MinimizeR™ Replacement Lens	20 ea/case



Occupational Health & Environmental Safety Division

3M Center - Building 235-2W-70
Saint Paul, MN 55144-1000

Sales Assistance: 1-800-328-1667

Technical Assistance: 1-800-243-4530

Website: www.3M.com/OccSafety

3M Canada

www.3M.ca/safety

Technical Assistance: 1-800-267-4414



WARNING!

These eye and face protection products help provide limited eye and face protection. Misuse or failure to follow warnings and instructions may result in serious potential injury, including blindness or death. For proper use, selection, and applications against flying particles, optical radiation and / or splash see supervisor, read User Instructions and warnings on the package or call 3M OH&ESD Technical Service in the USA at 1-800-243-4630. In Canada, call 1-800-267-4414.

Please recycle. Printed in USA.

© 2009 3M Company. All rights reserved. 3M, Maxim, MinimizeR and DX are trademarks of 3M Company.

AOSafety and AOS are trademarks of American Optical IP Corporation, used under license.

70-0715-6928-2