




# RECHARGEABLE HAND LAMP

240 lumens

**LED HANDLAMP, 3W, 240LM, FLASH/UV, RECHARGEABLE**

Grainger SKU	Description
40KG21	Rechargeable Hand Lamp
40KG17	

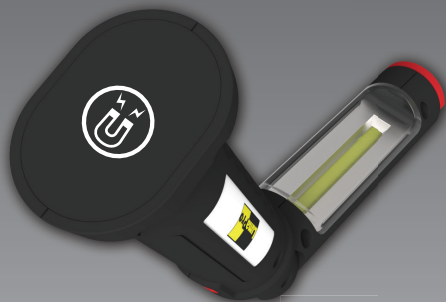

- The 3W single strip COB LED system produces an exceptionally bright floodlit work area.
- The 3W COB LED end light provides an additional directional flashlight / torch function.
- 3W Ultraviolet LED top light fluoresces leak detection dyes to pinpoint vehicle system leaks.
- Complete with super strong magnetic base.
- The lamp body rotates through 180° and pivots up to 120° allowing the operator to direct the strip light or torch accurately.
- Top mounted 360° rotating hanging hook.
- Lamp has built in automatic charging cut off, protecting the battery against overcharging.
- Versatile 2-in-1 charging system.
- Charge from 100-240V AC with included wall power plug.
- Charge from USB charging port with included USB cord.
- UL listed adaptor, RK-0501000, input 100-240V~50/60Hz 0.2A, output 5V 1A.



	Model	Volts	Watts	Lumen	LEDs	Battery	Housing Dimensions (In)	
							L	Dia
	40KG21	100-240V	3W	240 lm	COB/LED	3.7V 2200mAh	10-1/2	1-23/63
	40KG17	100-240V	3W	240 lm	COB/UV	3.7V 2200mAh	10-1/2	1-23/63

AVAILABLE THROUGH

**GRAINGER**

FOR THE ONES WHO GET IT DONE

For more information contact your Grainger Representative or visit Grainger.com