

# ALBION<sup>®</sup>

## CASTERS AND WHEELS

# Institutional Medium Duty Casters

- Double Row Swivel Raceways
- 3/8" Diameter Nut & Bolt Axle
- Heat Treated and Factory Lubricated Raceways

### Applications:


Hospital Equipment, Utility Carts, Store Fixtures, Office Equipment, Hotel Equipment, Institutional Equipment, Food Service Racks and Cases, Stock Carts, Laundry Trucks



Soft Rubber Wheel  
Swivel




TPR Rubber Wheel  
Swivel w/Brake

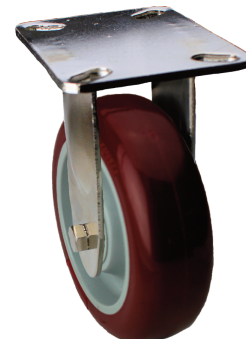

Polyurethane Wheel  
Rigid

Matches Up With the ER Wagner Americaster Series

Wheel Dia. (In.)	Tread Width (In.)	Load Rating (Lb.)	Wheel Bearing	Overall Height (In.)	Caster Finish	Swivel Part Number	Swivel W/Brake Part Number	Rigid Part Number
<b>Soft Rubber Wheel (Delrin Bearing)</b>								
4	1-1/4	200	Delrin	5-3/16	Nickel	02RR04151S002	02RR04151S001	02RR04151R001
5	1-1/4	240	Delrin	6-3/16	Nickel	02RR05151S002	02RR05151S001	02RR05151R001
6	1-1/4	280	Delrin	7-3/8	Nickel	02RR06151S002	02RR06151S001	02RR06151R001
<b>Thermoplastic Rubber Wheel (Delrin Bearing)</b>								
4	1-1/2	275	Delrin	5-3/16	Nickel	02XS04151S002	02XS04151S001	02XS04151R001
5	1-1/2	300	Delrin	6-3/16	Nickel	02XS05151S002	02XS05151S001	02XS05151R001
6	1-1/2	300	Delrin	7-3/8	Nickel	02XS06151S003	02XS06151S002	02XS06151R001
<b>Polyurethane Wheel (Delrin Bearing)</b>								
4	1-1/2	375	Delrin	5-3/16	Nickel	02XA04151S002	02XA04151S001	02XA04151R001
5	1-1/2	450	Delrin	6-3/16	Nickel	02XA05151S002	02XA05151S001	02XA05151R001
6	1-1/2	450	Delrin	7-3/8	Nickel	02XA06151S002	02XA06151S001	02XA06151R001
<b>Polyolefin Wheel (Delrin Bearing)</b>								
4	1-1/4	375	Delrin	5-3/16	Nickel	02PB04151S002	02PB04151S001	02PB04151R001
5	1-1/4	450	Delrin	6-3/16	Nickel	02PB05151S005	02PB05151S004	02PB05151R001
6	1-1/4	450	Delrin	7-3/8	Nickel	02PB06151S002	02PB06151S001	02PB06151R001

 

**Overall Size:** 3-1/8" x 4-1/8"  
**Hole Soacing:** 1-3/4" x 3 slotted  
to 2-3/8" x 3-3/8"  
**Bolt Dia.:** 5/16"

