

## VERTEX VENT A10V

Comfortable ventilated helmet for work at height and rescue



With its strong chin strap, the VERTEX VENT helmet sets the standard in head protection for workers at height. Ventilation holes with adjustable sliding shutters allow air to circulate in the helmet when needed. Its six-point mesh headband ensures comfort and its CenterFit adjustment system adjusts the headband and keeps it centered on the head. The VERTEX VENT is designed to optimally accept hearing protection, the specific VIZIR visor, or a PIXA headlamp.

### Selling points



- Six-point mesh headband forms to the shape of the head for improved comfort. Shock absorption achieved through deformation of the outer shell.
- CenterFit adjustment system ensures centering and optimal stability of the helmet on the head
- Ventilation holes with sliding shutters allow the ventilation to be adjusted as needed from the outside
- Side slots for mounting hearing protection
- Inserts for accepting a VIZIR visor
- Slot for mounting PIXA headlamp
- Four clips for mounting a headlamp with an elastic headband
- Chin strap designed to limit risk of losing helmet during a fall (strength greater than 50 daN)

### Specifications

- Size: 53-63 cm / 20.9-24.8 "
- Weight: 445 g / 15.7 oz
- Colors: yellow, red, white, orange, black, blue
- Certification:
  - CE EN 12492\*
  - UIAA
  - ANSI Z89.1-2009 Type I Class C

\*Meets requirements of EN 397 and EN 12492 standards in terms of protection against mechanical impacts

Meets optional requirements of EN 397 standard : lateral deformation, use in cold temperatures

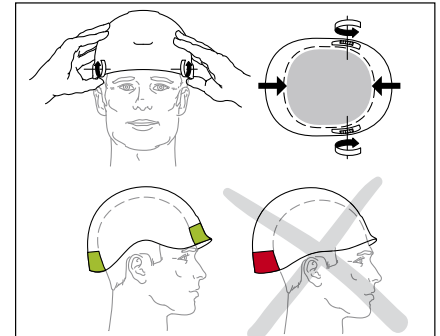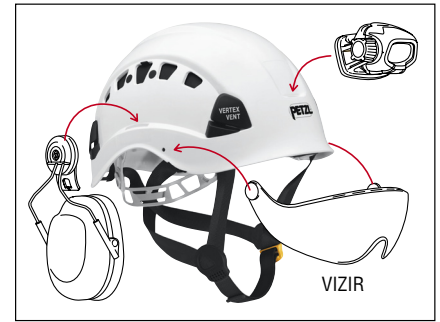

CenterFit adjustment system: The two adjustment wheels act simultaneously to adjust the headband and keep the helmet centered on the head. Adjustment wheels can be manipulated while wearing gloves.

- Made in France
- 3-year guarantee
- Materials: ABS, nylon, polycarbonate, high-strength polyester, polyethylene

### Related products

- VIZIR visor: A15
- Replacement foam: A10210
- Transparent stickers: A10100
- Reflective stickers : A10110

### Logistical information

Packing: x1  
Case quantity: x8  
EAN Codes:  
- A10VYA: 3342540089907  
- A10VWA: 3342540089877  
- A10VRA: 3342540089891  
- A10VNA: 3342540089884  
- A10VOA: 3342540089914  
- A10VBA: 3342540089921