

## ALVEO BEST A20B

Lightweight helmet for work at height and rescue



A20BYA



A20BRA



A20BWA

The ALVEO BEST is a lightweight helmet for workers at height. Its unventilated shell ensures protection against electrical risks and molten metal splash. Its CenterFit adjustment system adjusts the headband and keeps it centered on the head. The ALVEO BEST is designed to optimally accept hearing protection, the specific VIZIR visor, or a PIXA headlamp.



### Selling points

- Lightweight helmet with comfort foam that is barely felt on the head. Shock is absorbed by deformation of the expanded polystyrene liner.
- CenterFit adjustment system ensures centering and optimal stability of the helmet on the head
- Side slots for mounting hearing protection
- Inserts for accepting a VIZIR visor
- Slot for mounting PIXA headlamp
- Four clips for mounting a headlamp with an elastic headband
- Chin strap designed to limit risk of losing helmet during a fall (strength greater than 50 daN)
- Non-ventilated helmet protecting against electrical hazard and molten metal splash

### Specifications

- Size: 53-63 cm / 20.9-24.8 "
- Weight: 345 g / 12,2 oz
- Colors: yellow, red, white
- Certification:
  - CE\*
  - ANSI Z89.1-2009 Type I Class E

\* Meets requirements of EN 397 and EN 12492 standards in terms of protection against mechanical impacts  
 Meets requirements of EN 397 and EN 50365 standards in terms of electrical insulation  
 Meets optional requirements of the EN 397 standard : molten metal splash, lateral deformation, use in cold temperatures

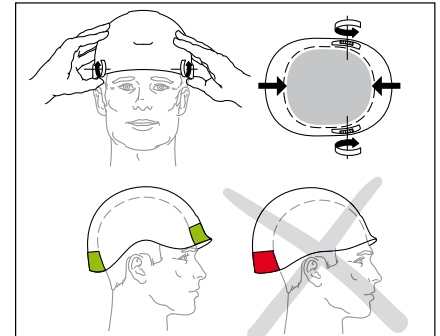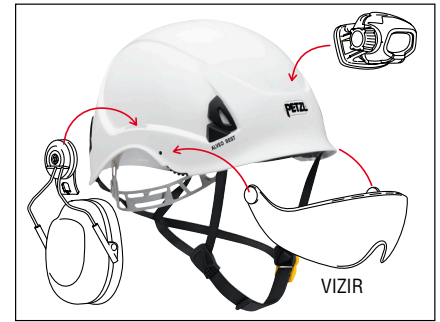

CenterFit adjustment system: The two adjustment wheels act simultaneously to adjust the headband and keep the helmet centered on the head. Adjustment wheels can be manipulated while wearing gloves.

- Made in France
- 3-year guarantee
- Materials: ABS, expanded polystyrene, nylon, polycarbonate, high-strength polyester, polyethylene

### Related products

- VIZIR visor: A15
- Replacement foam: A20210
- Absorbent foam: A20200
- Transparent stickers: A20100
- Reflective stickers : A20110

### Logistical information

Packing: x1  
 Case quantity: x8  
 EAN Codes:  
 - A20BYA: 3342540090347  
 - A20BWA: 3342540090323  
 - A20BRA: 3342540090330