



# FIREBOLT® STROBE BEACON

available in:



220100



220200

## Firebolt®

For dependable warning at an affordable price, count on the Firebolt line of strobe beacons. All models feature modular construction for easy installation and maintenance. Power supplies are moisture and vibration resistant, and will automatically adjust to function at multi-voltages (see specs.). The impact-resistant, polycarbonate dome and base provide added durability in heavy-duty applications. Permanent and magnetic mount models are available and include the necessary mounting hardware.

Firebolt models are available in 2-joule (single flash) and 5-joule (double flash) versions. The powerful 5-joule version with U-shaped strobe tube meets SAE Class 3. (The 2-joule version is available in 115VAC)

## Firebolt Plus

Firebolt Plus is available in a 2-joule (single flash) version and features a replaceable flash tube. The modular construction allows the flash tube to be easily replaced without the use of tools.

## > Features

- Automatic adjustment to function at multi-voltages
- Polycarbonate base available in permanent and magnetic models

## > Approvals

- 5-joule: SAE J845 Class 3 (SAE J1318 Class 3, 2009)

## > How to Order

### Specify Model

#### Firebolt

##### 2J, 2W, 12-72VDC, single flash

**220100-02** Permanent mount, Amber; -03(Blue);  
-04(Red); -05(Clear); -06(Green)

**210873-02** Magnetic mount, Amber; -03(Blue); -04(Red);  
-05(Clear); -06(Green)

##### 2J, 2W, 115VAC, single flash

**212356-02** Permanent mount, Amber; -03(Blue);  
-04(Red); -05(Clear); -06(Green)

##### 5J, 5.4W, 12-48VDC, double flash

**220105-02** Permanent mount, Amber; -03(Blue);  
-04(Red); -05(Clear)

**220110-02** Magnetic mount, Amber

#### Firebolt Plus

##### 2J, 2W, 12-72VDC, single flash

**220200-02** Permanent mount, Amber; -03(Blue);  
-04(Red); -05(Clear); -06(Green)

**220208-02** Magnetic mount, Amber; -03(Blue); -04(Red);  
-05(Clear); -06(Green)

#### Accessories and Kits

**210374** Kit, wiring, 10-ft, strobes

**210375** Kit, wiring, 20-ft, strobes

**210376** Kit, wiring, (2) strobes

**210377** Kit, wiring, 30-ft, strobes

**210539** "L" mounting bracket



**210728** Kit, magnetic mount with cigarette plug

**210850** Adapter, pipe mount, 3/4"

**210881** Adapter, pipe mount, 1/2"

**210862** Kit, mounting self-adhesive

**211676** Dome guard assembly, Chrome

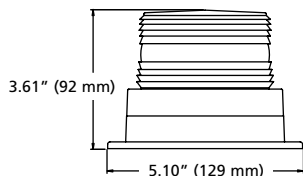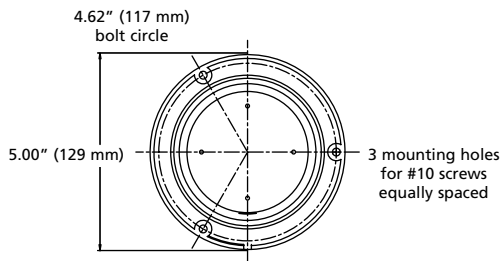

Specifications	
Flash Rate	60/min. (2J) 65/min. (5J)
Voltage	12-72 VDC (2J) 12-48 VDC (5J) 115 VAC (AC model)
Joules	2J (single flash) 5J (double flash)
Power	2W (single flash) 5.4W (double flash)
Amp Draw	0.24 @ 12V to 0.04 @ 72V (2 joule) 0.65 @ 12V to 0.17 @ 48V (5 joule) 0.02 @ 115V (AC model)
Ship Weight	
	0.7 lbs (0.3 kg)
Physical Specifications	
Diameter	5.0 in (127 mm)
Height	3.6 in (91 mm)



210374



210375



210376



210377



210728



210862



210850



210881



211676



210539