

HALOGEN

GOLIGHT®

Heavy duty lighting power for your work truck or any application where light is key to success

GOLIGHT® RADIORAY®

Model 2000


Remote Control Searchlight

- Cr5 Pentabeam™ Technology
- Wireless Hand Held Remote Controlled Operation
- 370° Rotation x 135° Tilt
- Permanent Mounting
- U.V. Ray and Salt Water Resistant
- 5.5 Amps with 12v Power Source (24v Optional)
- 3-Year Limited Warranty



Patent # - 5,673,989
& 5,490,046

Golight® Halogen Light Beam Dimensions

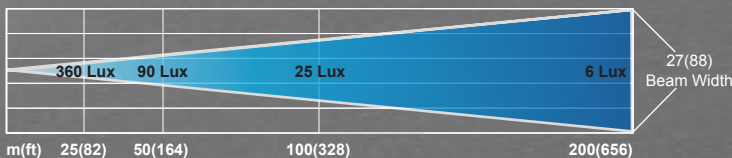

Illuminance (Lux) ■ 360 ■ 90 ■ 24 ■ 6

Peak Beam Intensity: 225,000 Candela
Maximum Beam Distance: 949 m / 3,113 ft
Beam Angle: 8°

Grainger Part Number:
Model 2000 Light (GP# - 3YXX3)

