

# HALOGEN

# GOLIGHT<sup>®</sup>

Heavy duty lighting power for your work truck or any application where light is key to success

## GOLIGHT<sup>®</sup> RADIORAY<sup>®</sup>

Model 7900

### Remote Control Searchlight


- Cr5 Pentabeam™ Technology
- Wireless Hand Held Remote Controlled Operation
- 370° Rotation x 135° Tilt
- Permanent and Portable Mounting Options
- U.V. Ray and Salt Water Resistant
- 5.5 Amps with 12v Power Source (24v Optional)
- 3-Year Limited Warranty

### GOLIGHT<sup>®</sup> & RADIORAY<sup>®</sup> ACCESSORIES

- Magnetic Mount Shoe - (16301)



### Golight<sup>®</sup> Halogen Light Beam Dimensions

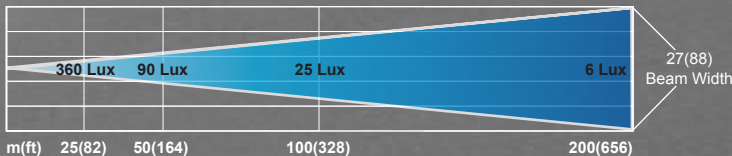

Illuminance (Lux) ■ 360 ■ 90 ■ 24 ■ 6

Peak Beam Intensity: 225,000 Candela

Maximum Beam Distance: 949 m / 3,113 ft

Beam Angle: 8°



Patent # - 5,673,989  
& 5,490,046

### Grainger Part Numbers:

Model 7900 Light (GP# - 3YXW9)

Model 16301 Shoe (GP# - 3YXX6)

