

DDL Dusk-to-Dawn

Multi-purpose LED Luminaire

- Rugged die-cast aluminum housing with both 2-3/8" & 1-5/8" OD mast arm mount capability as well as direct wall/surface mounting
- Less refractor provides zero uplight design for environmentally friendly installations
- Refractor included provides enhanced security lighting and LED brightness control when installed
- Three models from 2900-5200 lumens, 30-43.5w, up to 121 LPW efficacy
- Symmetric lens installed standard
- DDL-9L only: Field rotatable asymmetric lens included – for pathway/ roadway application
- 120V operation
- DDL-9L DesignLights Consortium qualified (DDL-56, DDL-140 in process)
- 120V twist-lock style photocontrol included
- Textured gray powder paint finish
- 24" (18" projection) arm included for DDL-9L and DDL-140L only, arm not included for DDL-56L
- ANSI 3G Rated



DUSK-TO-DAWN

ORDERING INFORMATION

Catalog Number	Construction	Mount	Wattage	Drive Current	Voltage	Color Temperature	Lumens	LPW	Weight lbs. (kg)
DDL-9L1	Die-cast aluminum	Arm/Wall/Surface	40	1280mA	120V	5000K	3437	86	6.8 (3.08)
DDL-56L-4K-1	Die-cast aluminum	Wall/Arm not included	30	150mA	120V	4000K	2906	97	6.8 (3.08)
DDL-140L-1	Die-cast aluminum	Wall/Arm included	43.5	92mA	120V	5000K	5279	121	6.8 (3.08)


PERFORMANCE INFORMATION

Series Number	Equivalency			Delivered Lumens	System Watts	Lumens Per Watt	Mounting Height	CCT	Voltage	LED Drivers/ Current
	MH	HPS	CFL							
DDL-9L1 (Symmetric lens)	100w	100w	85w	3437	40	86	up to 20 ft.	5000K	120V	1@1280mA
DDL-9L1 (Asymmetric lens)	100w	100w	85w	3246	40	81	up to 20 ft.	5000K	120V	1@1280mA
DDL-56L-4K-1	100w	100w	85w	2906	30	97	up to 15 ft.	4000K	120V	1@150mA
DDL-140L-1	175w	150w	125w	5279	43.5	121	up to 25 ft.	5000K	120V	1@92mA

ACCESSORIES/REPLACEMENT PARTS - Order Separately

Catalog Number	Description
ARM-DD24	24" aluminum arm with hardware
ARM-DD30	30" aluminum arm with hardware
DDL-DRIVER-120V	Driver for DDL9L (120V)
DDL-DRIVER-140	Diver for DDL-140L (120V)
DDL-DRIVER-56	Driver for DDL-56L (120V)
DDL-LENS-140	LED Asymmetric lens for DDL-140L
DDL-LENS2	LED Asymmetric lens for DDL-9L
DDL-LENS5	LED Symmetric lens for DDL-9L or DDL-56L
DDL-REFR	Refractor for all DDL models

DIMENSIONS

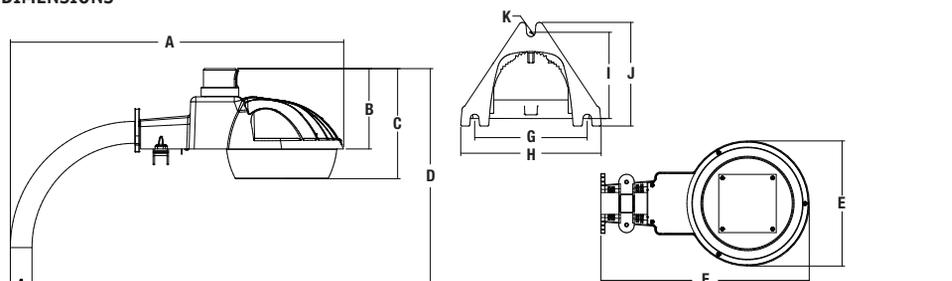

A	B	C	D	E	F	G	H	I	J	K
29.7"	6" or 4"	8.3"	16.2"	9.5"	16"	3.6"	4.5"	2.7"	3.3"	.14"
754 mm	152 mm	209 mm	411 mm	240 mm	406 mm	92 mm	115 mm	69 mm	84 mm	3.5mm

B Dimension = 4" without photocontrol



HUBBELL
Outdoor Lighting