

DEWALT®

HAMMER & CARBIDE REFERENCE GUIDE




GUARANTEED TOUGH.®

AVAILABLE THROUGH

GRAINGER®

FOR THE ONES WHO GET IT DONE

CONVENIENCE

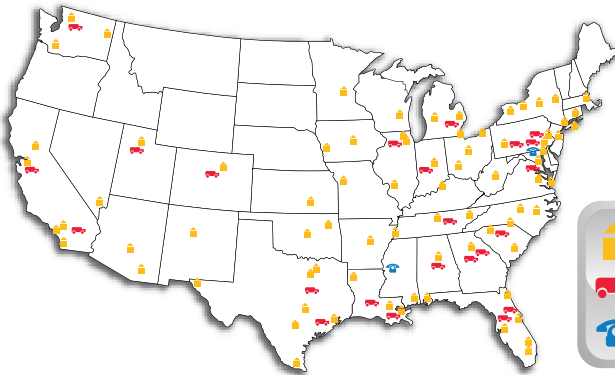

LARGEST SERVICE NETWORK

80+ Factory-Owned Service Centers

1,800+ Authorized Service Providers

1-800-4 DeWALT®

QUALITY



Get your tool back quickly...

with our 5-day turn-around time guarantee. Our factory trained technicians will perform a comprehensive inspection and parts replacement process to get your tool up and working.

- Safety Testing-Ensuring your tools are safe to operate
- We perform leakage current test, high pot test, and ground test on all repaired product
- A safety features check confirms that all safety required guarding shields and handles are available
- OSHA-recognized safety tag placed on all repairs
- Performance Testing –Repaired product tested by running through real-life applications prior to approvals
- Trained Technicians –Staff of over 250 professionally trained technicians ensure your repair is right the first time

COMMITMENT



Guaranteed Repair Cost Program:

- We offer repairs a smart option with the GRC Program
- We guarantee the repair will not exceed the quoted price
- GRC serves as an instant estimate allowing a quicker turnaround time (5 days or less)

**OFTEN LESS,
NEVER**



All DeWALT® rotary hammers with SHOCKS - Active Vibration Control® carry an industry leading 2-year free service agreement.

Your source for parts, manuals and product service 24/7/365.

www.servicenet.dewalt.com

ROTARY HAMMER INNOVATIONS

PERFORMANCE



MORE POWER, SIMILAR SIZE.*



COMFORT



SHOCKS 2
YEARS FREE SERVICE
ACTIVE VIBRATION CONTROL



CONTROL



Clutch Setting 1
Maximum Control
Maximum Torque Control
in Bind-up Situations



Clutch Setting 2
Maximum Torque
Standard Clutch
Setting for Large Holes

Automatically defaults to Clutch Setting 1 at initial plug-in.

COMPLETE DUST SOLUTION.™



DeWALT® provides a complete line of dust extraction solutions encompassing all DeWALT corded and cordless 7/8" and 1" SDS rotary hammers.

Ideal for controlling dust in occupied remodel jobs, data rooms, laboratories, public spaces and overhead applications.



* when compared to previous generation motor.

SHOCKS
ACTIVE VIBRATION CONTROL®

2
YEARS
FREE
SERVICE

50%
Less Vibration



**FEEL THE POWER,
NOT THE VIBRATION.®**



COMFORT



SHOCKS - Active Vibration Control®
dampens vibration before it impacts the operator, delivering improved comfort and overall productivity.

SDS ROTARY HAMMERS WITH SHOCKS-ACTIVE VIBRATION CONTROL®

D25223K/5LUP5

1" D-HANDLE SDS ROTARY HAMMER



SHOCKS **2**
ACTIVE VIBRATION CONTROL® YEARS FREE SERVICE

- SHOCKS – Active Vibration Control®
- Powerful 8.0 Amp motor
- 2.5 ft.-lbs. of impact energy
- Three-mode – Hammerdrill/Drill/Chipping



ALSO AVAILABLE
D25301D/5YAV7
Dust Extractor Telescope With Hose

D25323K/5LUP6

1" L-SHAPE SDS ROTARY HAMMER



SHOCKS **2**
ACTIVE VIBRATION CONTROL® YEARS FREE SERVICE

- SHOCKS – Active Vibration Control®
- Powerful 8.0 Amp motor
- 2.5 ft.-lbs. of impact energy
- Three-mode – Hammerdrill/Drill/Chipping



ALSO AVAILABLE
D25324K/5LUP7 1" L-Shape
SDS Hammer w/ Quick-Change
Chuck



D25300DH/1TAE8
Dust Extraction System with HEPA
Filter (see page 8)

PERFORMANCE



**8.0 Amp
Motor**

**2.5 ft.-lbs.
Impact Energy**

DURABILITY

**2
YEAR**
FREE
SERVICE

All 1" SDS Hammers with SHOCKS – Active Vibration Control® are backed by an industry leading 2 year free service contract.

D25213K/1TDA1

1" D-HANDLE SDS ROTARY HAMMER



ALSO AVAILABLE
D25113K/1TCZ8
1" Pistol Grip SDS Rotary Hammer

- Powerful 8.0 Amp motor
- 2.5 ft-lbs. of impact energy
- Three-mode – Hammerdrill/Drill/Chipping



D25313K/1TDA2

1" L-SHAPE SDS ROTARY HAMMER



- Powerful 8.0 Amp motor
- 2.5 ft-lbs. of impact energy
- Three-mode – Hammerdrill/Drill/Chipping



SDS DUST EXTRACTION SYSTEMS (See Page 8)



D25301D/5YAV7
Dust Extractor Telescope
with Hose



D25300DH/1TAE8
Dust Extraction System
with HEPA Filter
Fits L-Shape SDS
Hammers



D25302DH/5YAV8
Cordless Dust Extraction
System with HEPA Filter
Fits 36V SDS Hammers

SDS ROTARY HAMMERS

D25023K/5LUP4

7/8" COMPACT SDS ROTARY HAMMER



- Lightweight & Compact - 5.5 lbs.
- Powerful 6.9 Amp motor
- 1.8 ft-lbs. impact energy
- Three-mode – Hammerdrill/Drill/Chipping



ALSO AVAILABLE
D25012K/5LUP3
 7/8" Pistol Grip SDS Hammer
 (Dual-Mode)


D25404K/4YY97

1-1/8" SDS ROTARY HAMMER




- Powerful 8.3 Amp motor
- 3.34 ft-lbs. impact energy
- Three-mode – Hammerdrill/Drill/Chipping

SOLID ROCK CARBIDE SDS Plus







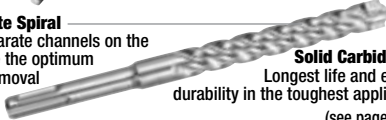




Solid carbide head and flute are bonded as one to offer the best SDS plus® drill bit durability

Four Flute Spiral
 Four separate channels on the flute give the optimum debris removal



Solid Carbide Head
 Longest life and extreme durability in the toughest applications
 (see page 9 & 10)

SDS ROTARY HAMMERS

SPECIFICATIONS									
Model #	D25012K/5LUP3	D25113K/1TCZ8	D25023K/5LUP4	D25213K/1TDA1	D25223K/5LUP5	D25313K/1TDA2	D25323K/5LUP6	D25324K/5LUP7	D25404K/4YY97
Max Capacity	7/8"	1"	7/8"	1"	1"	1"	1"	1"	1-1/8"
Amps	6.0	8.0	6.9	8.0	8.0	8.0	8.0	8.0	8.3
Impact Energy (ft-lbs.)	1.8	2.5	1.8	2.5	2.5	2.5	2.5	2.5	3.34
Active Vibration Control	No	No	No	No	SHOCKS®	No	SHOCKS®	SHOCKS®	No
RPM	0-1,550	0-1,150	0-1,550	0-1,150	0-1,150	0-1,150	0-1,150	0-1,150	0-730
BPM	0-4,150	0-4,300	0-4,550	0-4,300	0-4,300	0-4,300	0-4,300	0-4,300	0-4,100
Chipping	No	Yes	Yes	Yes	Yes	Yes	Yes	Yes	Yes
Removable Chuck	No	No	No	No	No	No	No	Yes	Yes
Weight	5.2 lbs.	5.7 lbs.	5.5 lbs.	6.1 lbs.	7.1 lbs.	6.5 lbs.	7.5 lbs.	7.8 lbs.	10.75 lbs.
Service Warranty	1 Year	1 Year	1 Year	1 Year	2 Year	1 Year	2 Year	2 Year	1 Year

DC212KL/4LEX6

7/8" 18V LI-ION SDS ROTARY HAMMER



- SHOCKS – Active Vibration Control®
- 1.7 ft-lbs. impact energy
- Compact L-Shape design
- Dual-mode: Hammerdrill/Drill



ALSO AVAILABLE
DC212B/4YEC2
18V 7/8" SDS Hammer (Tool Only)



DC233KL/1PJK8

1" 36V LI-ION SDS ROTARY HAMMER



- SHOCKS – Active Vibration Control®
- 1.9 ft-lbs. impact energy
- Compact L-Shape design
- Three-mode: Hammerdrill/Drill/Chipping



CORDLESS SDS ROTARY HAMMERS

SHOCKS 2
ACTIVE VIBRATION CONTROL®
YEARS FREE SERVICE



Significantly Reduces Vibration and Increases User Comfort and Productivity

SPECIFICATIONS					
	Tool Only		Lithium-Ion		Lithium-Ion
Model #	DC212B/4YEC2	DC212KA/1GEA4	DC212KL/4LEX6	DC223KA/1GEA5	DC233KL/1PJK8
Volts	18V	18V	18V	24V	36V
Impact Energy (ft-lbs.)	1.7	1.7	1.7	1.7	1.9
Vibration Control	SHOCKS®	SHOCKS®	SHOCKS®	SHOCKS®	SHOCKS®
RPM	0-1,100	0-1,100	0-1,100	0-1,100	0-1,150
BPM	0-4,100	0-4,100	0-4,100	0-4,100	0-4,400
Max Diameter	7/8"	7/8"	7/8"	7/8"	1"
Chipping	No	No	No	Yes	Yes
Weight	5.25 lbs.	7.6 lbs.	6.7 lbs.	8.4 lbs.	7.8 lbs.
Service Warranty	2 Year	2 Year	2 Year	2 Year	2 Year

SDS DUST EXTRACTION SYSTEMS



COMPLETE DUST SOLUTION.

DeWALT® provides a complete line of dust extraction solutions encompassing all DeWALT corded and cordless 7/8" and 1" SDS rotary hammers.

Ideal for controlling dust in occupied remodel jobs, data rooms, laboratories, public spaces and overhead applications.




D25302DH/5YAV8 CORDLESS DUST EXTRACTION SYSTEM WITH HEPA FILTER



(Rotary hammer sold separately)

- Built-in motor
- 2-Second shut-off delay
- HEPA Filter
- Cordless convenience

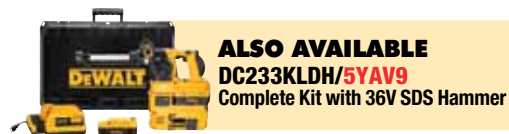

ALSO AVAILABLE
DC233KLDH/5YAV9
Complete Kit with 36V SDS Hammer

ALSO AVAILABLE D25301D/5YAV7

Dust Extractor Telescope With Hose







DUST EXTRACTOR TELESCOPE FITS



CORDED & CORDLESS

Dust Extractor Telescope with Hose fits Corded & Cordless DeWALT SDS Rotary Hammers
Compatible with Corded & Cordless Dust Extractor Vacuums
Lightweight - Weights only 1.4 lbs.

SDS DUST EXTRACTION SYSTEMS

SPECIFICATIONS				
Model #	D25302DH/5YAV8	DC233KLDH/5YAV9	D25301D/5YAV7	D25300DH/1TAE8
Built-In Motor	Yes	Yes	N/A	Yes
2-Second Shut-Off Delay	Yes	Yes	N/A	Yes
HEPA Filtration	Yes	Yes	N/A	Yes
Separate Vac Required	No	No	Yes	No
Fits DeWALT SDS Hammers	Cordless 36V & 28V	Includes: 36V SDS Hammer	Corded & Cordless except D25404	Corded L-Shaped except D25404


4 CUTTER



2 CUTTER



- **Thicker Rock Carbide® Tip**
Longer life
- **Stronger Flutes**
Increased steel prevents breakage
- **Elongated Four Flute Design**
Faster drilling
- **Open Head Design**
Faster mill removal

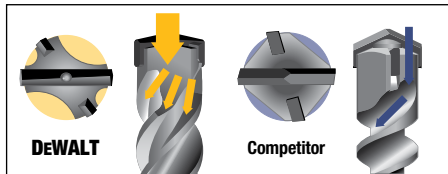

DW5470/4TG60
5 Piece Set:
3/16" x 4-1/2" x 6-1/2", 1/4" x 2" x 4", 1/4" x 4" x 6", 3/8" x 4" x 6", 1/2" x 4" x 6"



DW5366/1GEF8
10 Piece Anchor-Drive Installation Kit:
5/32" x 4" x 7"; 3/16" x 4" x 7" Drive Sleeve, Percussion Bit Holder, Insert Bit Adapter, #2 Insert Bit, #3 Insert Bit, 1/4" Nutsetter, 5/16" Nutsetter, Hex Key Medium Tough Case

Cat #	Description	Qty
SDS+ Steel		
DW5348/4LC57	10" Bull Point	1
DW5349/4LC58	10" Scraping Chisel	1
DW5350/4LC59	10" Cold Chisel	1
DW5351/4LC60	SDS To 1/2" Chuck Adaptor	1
DW5352	SDS To A Taper Adaptor	1
DW5353	1/2" Chuck and Key	1
SDS+ Hex Driver ("Tapcon®" Installation)		
DW5359/5MP42	5/32" x 2" x 5" SDS Hammer Bit with 1/4" Hex	1
DW5360/5MP43	5/32" x 3" x 6" SDS Hammer Bit with 1/4" Hex	1
DW5361/5MP44	5/32" x 4" x 7" SDS Hammer Bit with 1/4" Hex	1
DW5362/5MP45	3/16" x 2" x 5" SDS Hammer Bit with 1/4" Hex	1
DW5363/5MP46	3/16" x 3" x 6" SDS Hammer Bit with 1/4" Hex	1
DW5364/5MP47	3/16" x 4" x 7" SDS Hammer Bit with 1/4" Hex	1
DW5364B25	3/16" x 4" x 7" SDS Hammer Bit with 1/4" Hex	Bulk 25
DW5365/5MP48	Drill Sleeve For Hex SDS Hammer Bit	1
SDS+ Rock Carbide (2-Cutter)		
DW5400/4DV46	5/32" x 2" x 4" Rock Carbide™ SDS+ Hammer Bit	1
DW5401/4TF99	5/32" x 4-1/2" x 6-1/2" Rock Carbide™ SDS+ Hammer Bit	1
DW5401B25/4TG01	5/32" x 4-1/2" x 6-1/2" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5402/4TG02	3/16" x 2" x 4" Rock Carbide™ SDS+ Hammer Bit	1
DW5402B25/1ELE8	3/16" x 2" x 4" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5403	3/16" x 4-1/2" x 6-1/2" Rock Carbide™ SDS+ Hammer Bit	1
DW5403B25	3/16" x 4-1/2" x 6-1/2" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5404/4TG06	3/16" x 6-1/2" x 8-1/2" Rock Carbide™ SDS+ Hammer Bit	1
DW5404B25/4TG07	3/16" x 6-1/2" x 8-1/2" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5405/4TG08	3/16" x 8" x 10" Rock Carbide™ SDS+ Hammer Bit	1
DW5405B25/4TG09	3/16" x 8" x 10" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5406/4TG10	3/16" x 10" x 12" Rock Carbide™ SDS+ Hammer Bit	1
DW5406B25/4TG11	3/16" x 10" x 12" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5407/4TG12	3/16" x 12" x 14" Rock Carbide™ SDS+ Hammer Bit	1
DW5408/4TG13	3/16" x 14" x 16" Rock Carbide™ SDS+ Hammer Bit	1
DW5410/4TG14	7/32" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	1
DW5410B25/4TG15	7/32" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	Bulk
DW5412/4TG16	7/32" x 8" x 10" Rock Carbide™ SDS+ Hammer Bit	1

Tapcon is a registered trademark of ITW Buildex.

SDS PLUS BITS

Cat #	Description	Qty
SDS+ Rock Carbide (2-Cutter) continued		
DW5416/4TG17	1/4" x 2" x 4" Rock Carbide™ SDS+ Hammer Bit	1
DW5416B25/4TG18	1/4" x 2" x 4" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5417/4TG19	1/4" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	1
DW5417B25/1ELF1	1/4" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5418/4TG21	1/4" x 6-1/2" x 8-1/2" Rock Carbide™ SDS+ Hammer Bit	1
DW5418B25/1ELG3	1/4" x 6-1/2" x 8-1/2" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5420/4TG23	1/4" x 10" x 12" Rock Carbide™ SDS+ Hammer Bit	1
DW5421/4TG24	1/4" x 12" x 14" Rock Carbide™ SDS+ Hammer Bit	1
DW5424/4TG25	5/16" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	1
DW5424B25/4TG26	5/16" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5426/4TG27	5/16" x 10" x 12" Rock Carbide™ SDS+ Hammer Bit	1
DW5427/4TG28	3/8" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	1
DW5427B25/1ELF2	3/8" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5429/4TG30	3/8" x 8" x 10" Rock Carbide™ SDS+ Hammer Bit	1
DW5430/4TG31	3/8" x 10" x 12" Rock Carbide™ SDS+ Hammer Bit	1
DW5431/4TG32	3/8" x 16" x 18" Rock Carbide™ SDS+ Hammer Bit	1
DW5432/4TG33	3/8" x 22" x 24" Rock Carbide™ SDS+ Hammer Bit	1
DW5433/4TG34	7/16" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	1
DW5435/4TG35	7/16" x 10" x 12" Rock Carbide™ SDS+ Hammer Bit	1
DW5436/4DV47	7/16" x 16" x 18" Rock Carbide™ SDS+ Hammer Bit	1
DW5437/4TG36	1/2" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	1
DW5437B25/1ELF3	1/2" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5438/4TG38	1/2" x 8" x 10" Rock Carbide™ SDS+ Hammer Bit	1
DW5439/4TG39	1/2" x 10" x 12" Rock Carbide™ SDS+ Hammer Bit	1
DW5440/4TG40	1/2" x 16" x 18" Rock Carbide™ SDS+ Hammer Bit	1
DW5441/4TG41	1/2" x 22" x 24" Rock Carbide™ SDS+ Hammer Bit	1
DW5442/4TG42	9/16" x 4" x 6" Rock Carbide™ SDS+ Hammer Bit	1
DW5443/4TG43	9/16" x 10" x 12" Rock Carbide™ SDS+ Hammer Bit	1
DW5444/4TG44	9/16" x 16" x 18" Rock Carbide™ SDS+ Hammer Bit	1
DW5445/4DV48	9/16" x 22" x 24" Rock Carbide™ SDS+ Hammer Bit	1
DW5446/4TG45	5/8" x 6" x 8" Rock Carbide™ SDS+ Hammer Bit	1
DW5446B25	5/8" x 6" x 8" Rock Carbide™ SDS+ Hammer Bit	Bulk 25
DW5447/4TG47	5/8" x 10" x 12" Rock Carbide™ SDS+ Hammer Bit	1
DW5448/4TG48	5/8" x 16" x 18" Rock Carbide™ SDS+ Hammer Bit	1
DW5449/4TG49	5/8" x 22" x 24" Rock Carbide™ SDS+ Hammer Bit	1
DW5450/4TG50	11/16" x 6" x 8" Rock Carbide™ SDS+ Hammer Bit	1
DW5453/4TG51	3/4" x 6" x 8" Rock Carbide™ SDS+ Hammer Bit	1
DW5455/4TG52	3/4" x 10" x 12" Rock Carbide™ SDS+ Hammer Bit	1
DW5456/4TG53	3/4" x 16" x 18" Rock Carbide™ SDS+ Hammer Bit	1
DW5457/4TG54	3/4" x 22" x 24" Rock Carbide™ SDS+ Hammer Bit	1
DW5458/4DV49	27/32" x 6" x 8" Rock Carbide™ SDS+ Hammer Bit	1
DW5460/4TG55	7/8" x 6" x 8" Rock Carbide™ SDS+ Hammer Bit	1
DW5461/4TG56	7/8" x 10" x 12" Rock Carbide™ SDS+ Hammer Bit	1
DW5462/4TG57	7/8" x 16" x 18" Rock Carbide™ SDS+ Hammer Bit	1
DW5464/4TG58	1" x 8" x 10" Rock Carbide™ SDS+ Hammer Bit	1
DW5466/4TG59	1" x 16" x 18" Rock Carbide™ SDS+ Hammer Bit	1
DW5468/4DV50	1-1/8" x 8" x 10" Rock Carbide™ SDS+ Hammer Bit	1
DW5469/4DC51	1-1/8" x 16" x 18" Rock Carbide™ SDS+ Hammer Bit	1
DW5470/4TG60	5-Piece Rock Carbide™ SDS+ Hammer Bit Set	5

Cat #	Description	Qty
SDS+ Solid Rock Carbide (Full Head Carbide)		
DW5502/2PRD8	3/16" x 2" x 4-1/2" Solid Carbide Rock™ SDS+	1
DW5503	3/16" x 4" x 6-1/2" Solid Rock Carbide™ SDS+	1
DW5504/2PRE3	3/16" x 6" x 8-1/2" Solid Rock Carbide™ SDS+	1
DW5505	3/16" x 8" x 10-1/2" Solid Rock Carbide™ SDS+ Bit	1
DW5506/2PRE7	3/16" x 10" x 12" Solid Rock Carbide™ SDS+	1
DW5507/2PRE9	3/16" x 12" x 14" Solid Rock Carbide™ SDS+	1
DW5510	7/32" x 4" x 6-1/2" Solid Rock Carbide™ SDS+	1
DW5512/2PRF3	7/32" x 8" x 10" Solid Rock Carbide™ SDS+	1
DW5516/2PRF4	1/4" x 2" x 4-1/2" Solid Rock Carbide™ SDS+ Hammer Bit	1
DW5517/2PRF6	1/4" x 4" x 6" Solid Rock Carbide™ SDS+	1
DW5518	1/4" x 6" x 8-1/2" Solid Rock Carbide™ SDS+	1
DW5520	1/4" x 10" x 12" Solid Rock Carbide™ SDS+	1
DW5521/2PRG1	1/4" x 12" x 14" Solid Rock Carbide™ SDS+	1
DW5524/2PRG2	5/16" x 4" x 6-1/2" Solid Rock Carbide™ SDS+	1
DW5526/2PRG4	5/16" x 10" x 12" Solid Rock Carbide™ SDS+	1
DW5527/2PRG5	3/8" x 4" x 6-1/2" Solid Rock Carbide™ SDS+	1
DW5529/2PRG7	3/8" x 8" x 10" Solid Rock Carbide™ SDS+	1
DW5530	3/8" x 10" x 12" Solid Rock Carbide™ SDS+	1
DW5531/2PRG8	3/8" x 16" x 18" Solid Rock Carbide™ SDS+	1
DW5532/2PRG9	3/8" x 21" x 23-1/2" Solid Rock Carbide™ SDS+	1
DW5537/4YEC4	1/2" x 4" x 6" Solid Rock Carbide™ SDS+	1
DW5538/4YEC6	1/2" x 8" x 10-1/2" Solid Rock Carbide™ SDS+	1
DW5539/4YEC7	1/2" x 10" x 12" Solid Rock Carbide™ SDS+	1
DW5540/4YEC8	1/2" x 16" x 18" Solid Rock Carbide™ SDS+	1
DW5541	1/2" x 22" x 24" Solid Rock Carbide™ SDS+	1
DW5502B25/2PRD9	3/16" x 2" x 4-1/2" Solid Rock Carbide™ SDS+	Bulk 25
DW5503B25/2PRE2	3/16" x 4" x 6-1/2" Solid Rock Carbide™ SDS+ Bit	Bulk 25
DW5504B25/2PRE4	3/16" x 6" x 8-1/2" Solid Rock Carbide™ SDS+	Bulk 25
DW5505B25	3/16" x 8" x 10-1/2" Solid Rock Carbide™ SDS+	Bulk 25
DW5506B25/2PRE8	3/16" x 10" x 12" Solid Rock Carbide™ SDS+	Bulk 25
DW55100B25/2PRF2	7/32" x 4" x 6-1/2" Solid Rock Carbide™ SDS+	Bulk 25
DW5516B25/2PRF5	1/4" x 2" x 4-1/2" Solid Rock Carbide™ SDS+	Bulk 25
DW5517B25/2PRF7	1/4" x 4" x 6" Solid Rock Carbide™ SDS+	Bulk 25
DW5518B25/2PRF9	1/4" x 6" x 8-1/2" Solid Rock Carbide™ SDS+	Bulk 25
DW5524B25/2PRG3	5/16" x 4" x 6-1/2" Solid Rock Carbide™ SDS+	Bulk 25
DW5527B25/2PRG6	3/8" x 4" x 6-1/2" Solid Rock Carbide™ SDS+	Bulk 25
DW5537B25/4YEC5	1/2" x 4" x 6" Solid Rock Carbide™ SDS+	Bulk 25
SDS+ 4 Cutter		
DW5471/2KLJ1	5/8" x 8" x 10" Rock Carbide™) 4 Cutter SDS+ Hammer Bit	1
DW5472/2KLJ2	5/8" x 16" x 18" Rock Carbide™) 4 Cutter SDS+ Hammer Bit	1
DW5474/2KLJ3	3/4" x 8" x 10" Rock Carbide™) 4 Cutter SDS+ Hammer Bit	1
DW5475/2KLJ4	3/4" x 16" x 18" Rock Carbide™) 4 Cutter SDS+ Hammer Bit	1
DW5477/2KLJ5	7/8" x 8" x 10" Rock Carbide™) 4 Cutter SDS+ Hammer Bit	1
DW5478/2KLJ6	7/8" x 16" x 18" Rock Carbide™) 4 Cutter SDS+ Hammer Bit	1
DW5479/2KLJ7	1" x 8" x 10" Rock Carbide™) 4 Cutter SDS+ Hammer Bit	1
DW5480/2KLJ8	1" x 16" x 18" Rock Carbide™) 4 Cutter SDS+ Hammer Bit	1
DW5481/2KLJ9	1-1/8" x 8" x 10" Rock Carbide™) 4 Cutter SDS+ Hammer Bit	1
DW5482/2KLK1	1-1/8" x 16" x 18" Rock Carbide™) 4 Cutter SDS+ Hammer Bit	1

CTC COMPLETE TORQUE CONTROL®



Clutch Setting 1 Maximum Control

Maximum Torque Control
in Bind-up Situations

Clutch Setting 2 Maximum Torque

Standard Clutch
Setting for Large Holes

Automatically defaults to Clutch Setting 1 at initial plug-in.



CONTROL




CTC COMPLETE TORQUE CONTROL®

Patented 2-Stage Clutch



Clutch Setting 1

Ideal for most applications

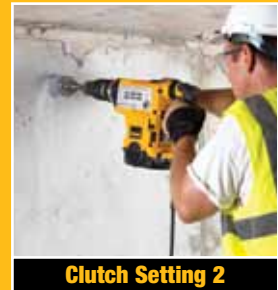

Clutch Setting 2

Core bits or deep hole drilling

SDS MAX & SPLINE COMBINATION ROTARY HAMMERS

D25602K/5YAW3 1-3/4" SDS MAX COMBINATION ROTARY HAMMER

Spring Loaded Beat Piece Seal
Keeps dust out of impact mechanism

Rear Handle Mount
For increased user comfort in down drilling applications

SHOCKS 2
ACTIVE VIBRATION CONTROL
2 YEARS FREE SERVICE

CTC
COMPLETE TORQUE CONTROL®

Utilizes a DeWALT® patented 2-stage clutch for maximum control in bind-up situations

9.5 ft-lbs. of Impact Energy
Provides fast drilling and powerful chipping

Trigger Lock-On
Reduces user fatigue while chipping

Electronic Variable Speed
Matches the speed of drilling and chipping to the application while maintaining speed under load



New Spline Tool Holder
Easier to insert bits
*Only available on the D25651K

13.5 Amp Motor, 210-415 RPM, 1,430-2,840 BPM
Provides high performance and overload protection



ALSO AVAILABLE
D25651K/5YAW4
1-3/4" Spline Combination Rotary Hammer

REAR HANDLE MOUNT

DeWALT's exclusive rear handle mount design increases comfort in down drilling applications.



TWO-HANDED HANDLE

DeWALT's two-handed handle design reduces fatigue and increases user comfort.



PERFORMANCE



13.5 Amp Motor

9.5 ft-lbs. Impact Energy



SHOCKS 2
ACTIVE VIBRATION CONTROL
2 YEARS FREE SERVICE

Up To Less Vibration

DURABILITY

2 YEAR
FREE SERVICE

All DeWALT® Hammers with SHOCKS – Active Vibration Control® are backed by an industry leading 2 year free service contract.

D25762K/5YAW7

2" SDS MAX COMBINATION ROTARY HAMMER



- SHOCKS – Active Vibration Control®
- Complete Torque Control (CTC)®
- Powerful 15.0 Amp motor
- 15.0 ft-lbs. of impact energy



D25712K/5YAW6

1-7/8" SDS MAX COMBINATION ROTARY HAMMER



- SHOCKS – Active Vibration Control®
- Complete Torque Control (CTC)®
- Powerful 13.0 Amp motor
- 11.7 ft-lbs. of impact energy



15.0 Amp Motor

15.0 ft-lbs. Impact Energy

COMFORT

SHOCKS 2 YEARS FREE SERVICE ACTIVE VIBRATION CONTROL

Up To Less Vibration

CONTROL

CTC COMPLETE TORQUE CONTROL

Patented 2-Stage Clutch

SDS MAX & SPLINE COMBINATION ROTARY HAMMERS

D25501K/5YAW0

1-9/16" SDS MAX COMBINATION ROTARY HAMMER



- Powerful 12.0 Amp motor
- 8.0 ft-lbs. of impact energy
- Lightweight & compact - 13.55 lbs.
- Rear handle mount



ALSO AVAILABLE
D25553K/5YAW1 -
 1-9/16" Spline Combination
 Rotary Hammer

PERFORMANCE



12.0 Amp
Motor

8.0 ft-lbs.
Impact Energy

COMFORT



Rear Handle Mount
 Increased comfort in
 down drilling applications







EASE OF USE



New Spline Tool Holder
 Easier to insert bits

COMBINATION ROTARY HAMMERS



SPECIFICATIONS						
Model #	D25501K/5YAW0	D25553K/5YAW1	D25602K/5YAW3	D25651K/5YAW4	D25712K/5YAW6	D25762K/5YAW7
Bit Style	SDS Max	Spline	SDS Max	Spline	SDS Max	SDS Max
Max Capacity	1-9/16"	1-9/16"	1-3/4"	1-3/4"	1-7/8"	2"
Amps	12.0	12.0	13.5	13.5	13.0	15.0
Impact Energy (ft-lbs.)	8.0	8.0	9.5	9.5	11.7	15.0
Active Vibration Control	No	No	SHOCKS®	SHOCKS®	SHOCKS®	SHOCKS®
Complete Torque Control (CTC)®	No	No	Yes	Yes	Yes	Yes
RPM	490	490	210-415	210-415	137-275	125-250
BPM	3,300	3,300	1,430-2,840	1,430-2,840	1,260-2,520	1,150-2,304
Weight	13.55 lbs.	14.0 lbs.	15.1 lbs.	15.5 lbs.	17.5 lbs.	19.2 lbs.

DEWALT® DEMOLITION HAMMERS

D25831K/5YAW2

SDS MAX CHIPPING HAMMER



SHOCKS 2
ACTIVE VIBRATION CONTROL
YEARS FREE SERVICE

- SHOCKS – Active Vibration Control®
- High-performance 13.5 Amp motor
- 9.5 ft-lbs. impact energy



ALSO AVAILABLE
D25851K/5YAW5 -
Round Hex Chipping Hammer



ALSO AVAILABLE
D25891K/5YAW8 - SDS MAX
Demolition Hammer
15.0 Amps / 15.0 ft-lbs.

D25901K/2NER4

SDS MAX DEMOLITION HAMMER



SHOCKS 2
ACTIVE VIBRATION CONTROL
YEARS FREE SERVICE

- SHOCKS – Active Vibration Control®
- Powerful 14.0 Amp motor
- 3.7 - 18.5 ft-lbs. impact energy
- 1-Step 12-position chisel rotation



ALSO AVAILABLE
D25941K/2NER5
3/4" Hex Demolition Hammer
15.0 Amps/22.0 ft-lbs.



ALSO AVAILABLE
D25899K/2NER3
SDS MAX Demolition Hammer
14.0 Amps/18.5 ft-lbs.

CHIPPING & DEMOLITION HAMMERS



SPECIFICATIONS						
Model #	D25831K/5YAW2	D25851K/5YAW5	D25891K/5YAW8	D25899K/2NER3	D25901K/2NER4	D25941K/2NER5
Bit Style	SDS Max	Round Hex	SDS Max	SDS Max	SDS Max	3/4" Hex
Amps	13.5	13.5	15.0	14.0	14.0	15.0
Impact Energy (ft-lbs)	9.5	9.5	15.0	18.5	18.5	22.0
Active Vibration Control	SHOCKS®	SHOCKS®	SHOCKS®	No	SHOCKS®	SHOCKS®
BPM	1,430-2,840	1,430-2,840	1,152-2,304	2,040	1,020-2,040	1,620
Weight	13.6 lbs.	14.0 lbs.	19.0 lbs.	21.2 lbs.	21.6 lbs.	27.2 lbs.
Service Warranty	2 Year	2 Year	2 Year	1 Year	2 Year	2 Year

PAVEMENT BREAKER

D25980KB/1TDA5

PAVEMENT BREAKER WITH HAMMER TRUCK




- **SHOCKS – Active Vibration Control®**
- **Powerful 15.0 Amp motor**
- **61.0 ft-lbs. impact energy**
- **Portability – hammer truck**



SHOCKS **2**
ACTIVE VIBRATION CONTROL®
 YEARS
 FREE
 SERVICE


PERFORMANCE

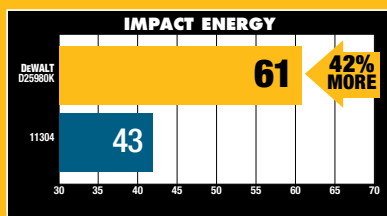

DeWALT's Larger Ram Delivers **42% More** Impact Energy than the leading competitor



COMFORT

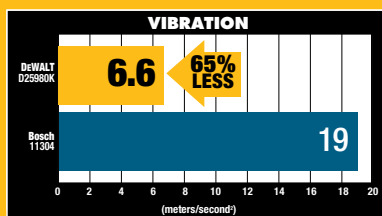

SHOCKS – Active Vibration Control® reduces user fatigue and increases comfort and productivity

SHOCKS
 ACTIVE VIBRATION CONTROL



PORTABILITY



- Can carry the breaker with the bit in or out for convenient transporting
- Doubles as a jobsite hand truck
- Retention system secures the bits in the cart
- Ramp on back for easier loading

 
Rock Carbide® Tip
Maximizes carbide surface contact for longer life



Open Head Design
Increased free space channels more dust out

Four Flute Design
Cleans debris out for fast, efficient drilling

Longer Helix
Increased flute travel expedites mill removal



Cat #	Description	Qty
SDS Max		
DW5801/5MP60	9/16" x 8" x 13-1/2" 2 Cutter SDS Max Rotary Hammer Bit	1
DW5802/5MP61	9/16" x 16" x 21-1/2" 2 Cutter SDS Max Rotary Hammer Bit	1
DW5803/4LD33	1/2" x 8" x 13-1/2" 2 Cutter SDS Max Rotary Hammer Bit	1
DW5804/4LD34	1/2" x 16" x 21-1/2" 2 Cutter SDS Max Rotary Hammer Bit	1
DW5806/4LD35	5/8" x 8" x 13-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5807/5MP62	5/8" x 31" x 36" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5808/5MP63	11/16" x 16" x 21-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5809/4LD36	5/8" x 16" x 21-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5810/4LD37	3/4" x 8" x 13-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5812/4LD38	3/4" x 16" x 21-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5813/5MP64	3/4" x 31" x 36" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5814/5MP65	13/16" x 16" x 21-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5815/4LD39	7/8" x 8" x 13-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5816/4LD40	7/8" x 16" x 21-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5817	27/32" x 16" x 21-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5818/4LD41	1" x 8" x 13-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5819/4LD42	1" x 16" x 21-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5820/5MP67	1" x 31" x 36" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5821/4LD43	1-1/8" x 10" x 15" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5822/4LD44	1-1/8" x 18" x 22-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5823	1-1/16" x 18" x 22-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5824/4LD45	1-1/4" x 10" x 15" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5825/4LD46	1-1/4" x 18" x 22-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5826/5MP69	1-1/4" x 31" x 36" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5827/4LD47	1-3/8" x 18" x 22-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5828/4LD48	1-1/2" x 18" x 22-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5829/4PC27	1-7/16" x 18" x 22-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5830/4PC28	1-3/4" x 18" x 22-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5831/4PC29	2" x 18" x 22-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
Spline 2 Cutter		
DW5700/4LC66	3/8" x 5" x 10" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5701/4LC67	3/8" x 8" x 13" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5702/4LC68	7/16" x 5" x 10" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5703/4LC69	1/2" x 5" x 10" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5704/4LC70	1/2" x 11" x 16" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5705/4LC71	1/2" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5706/4LC72	1/2" x 22" x 27" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5707/4LC73	1/2" x 31" x 36" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5708/4LC74	9/16" x 5" x 10" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5735/1GEF9	9/16" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5709/4LC75	5/8" x 5" x 10" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5710/4LC76	5/8" x 11" x 16" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5711/4LC77	5/8" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5712/4LC78	5/8" x 22" x 27" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5713/4LC79	11/16" x 5" x 10" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5714/4LC80	3/4" x 5" x 10" 2 Cutter Spline Shank Rotary Hammer Bit	1

Cat #	Description	Qty
DW5715/4LC81	3/4" x 11" x 16" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5716/4LC82	3/4" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5717/4LC83	3/4" x 22" x 27" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5719/4LC84	7/8" x 11" x 16" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5720/4LC85	7/8" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5721/4LC86	1" x 11" x 16" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5722/4LC87	1" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5723	1" x 31" x 36" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5724	1-1/8" x 5" x 10" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5725/4LC90	1-1/8" x 11" x 16" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5726/4LC91	1-1/8" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5727/4LC92	1-1/4" x 11" x 16" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5728/4LC93	1-1/4" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5729/4LC94	1-3/8" x 11" x 16" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5730/4LC95	1-3/8" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5731/4LC96	1-1/2" x 11" x 16" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5732/4LC97	1-1/2" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5733/4LC98	1-3/4" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
DW5734/4LC99	2" x 17" x 22" 2 Cutter Spline Shank Rotary Hammer Bit	1
Spline 4 Cutter		
DW5740/4LD01	5/8" x 5" x 10" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5741/4LD02	5/8" x 11" x 16" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5742/4LD03	5/8" x 17" x 22" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5743/4LD04	5/8" x 22" x 27" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5744/5MP49	5/8" x 31" x 36" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5745/5MP50	11/16" x 11" x 16" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5746/4LD05	3/4" x 5" x 10" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5747/4LD06	3/4" x 11" x 16" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5748/4LD07	3/4" x 17" x 22" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5749/4LD08	3/4" x 22" x 27" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5750/5MP51	3/4" x 31" x 36" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5751	27/32" x 11" x 16" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5752/4LD09	7/8" x 11" x 16" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5753/4LD10	7/8" x 17" x 22" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5755/4LD11	1" x 11" x 16" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5756/4LD12	1" x 17" x 22" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5757/5MP53	1" x 31" x 36" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5758/4LD13	1-1/8" x 11" x 16" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5759/4LD14	1-1/8" x 17" x 22" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5760/4LD15	1-1/4" x 11" x 16" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5761/4LD16	1-1/4" x 17" x 22" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5762/5MP54	1-1/4" x 31" x 36" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5763/4LD17	1-3/8" x 11" x 16" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5764/4LD18	1-1/2" x 17" x 22" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5765/5MP55	1-3/8" x 17" x 22" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5768/5MP56	1-3/4" x 17" x 22" 4 Cutter Spline Shank Rotary Hammer Bit	1
DW5769/5MP57	2" x 17" x 22" 4 Cutter Spline Shank Rotary Hammer Bit	1

SDS MAX & SPLINE BITS, CHISELS, & STEEL

Cat #	Description	Qty
SDS Max Steel		
DW5832/4LD49	12" Bull Point Bit SDS Max Shank	1
DW5832B15	12" Bull Point Bit SDS Max Shank (Bulk)	15
DW5833/4LD50	18" Bull Point Bit SDS Max Shank	1
DW5833B15	18" Bull Point Bit SDS Max Shank (Bulk)	15
DW5834/4LD51	1" x 12" Cold Chisel SDS Max Shank	1
DW5834B15/4CY90	1" x 12" Cold Chisel SDS Max Shank (Bulk)	15
DW5835/4LD52	18" Cold Chisel SDS Max Shank	1
DW5835B15	18" Cold Chisel SDS Max Shank (Bulk)	15
DW5837/4LD54	2" x 15" Scaling Chisel SDS Max Shank	1
DW5838/5MP70	3" x 12" Scaling Chisel SDS Max Shank	1
DW5838B10/4CY91	3" x 12" Scaling Chisel SDS Max Shank (Bulk)	10
DW5842/4LD55	12" Slotting Tool SDS Max Shank	1
DW5843/4LD56	12" x 1-3/8" Bushing Tool SDS Max Shank	1
DW5843B10	12" x 1-3/8" Bushing Tool SDS Max Shank (Bulk)	10
DW5847/4LD57	Ground Rod Driver SDS Max Shank	1
DW5848B/1EC34	4" Clay Spade (Bulk)	1
DW5860	1-5/16" x 18" x 22-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5861/5MP72	1-9/16" x 18" x 22-1/2" 4 Cutter SDS Max Rotary Hammer Bit	1
DW5891/3LA74	SDS Max to SDS+ Adaptor	1
Spline Steel (3/4" Hex x 21/32" Round Spline Shank)		
DW5770/4LD19	12" Bull Point 3/4" Hex x 21/32" Round Spline Shank	1
DW5770B15	12" Bull Point 3/4" Hex x 21/32" Round Spline Shank (Bulk)	15
DW5771/4LD20	18" Bull Point 3/4" Hex x 21/32" Round Spline Shank	1
DW5771B15	18" Bull Point 3/4" Hex x 21/32" Round Spline Shank (Bulk)	15
DW5772/4LD21	1-1/2" x 12" Slotting Chisel 3/4" Hex x 21/32" Round Spline Shank	1
DW5773/4LD22	1-1/4" x 12" Scaling Chisel 3/4" Hex x 21/32" Round Spline Shank	1
DW5774/4LD23	2" x 12" Scaling Chisel 3/4" Hex x 21/32" Round Spline Shank	1
DW5775/5MP58	3" x 12" Scaling Chisel 3/4" Hex x 21/32" Round Spline Shank	1
DW5775B10	3" x 12" Scaling Chisel 3/4" Hex x 21/32" Round Spline Shank Bulk	10
DW5779/4LD24	1" x 12" Cold Chisel 3/4" Hex x 21/32" Round Spline Shank	1
DW5779B15	1" x 12" Cold Chisel 3/4" Hex x 21/32" Round Spline Shank Bulk	15
DW5780/4LD25	1" x 18" Cold Chisel 3/4" Hex x 21/32" Round Spline Shank	1
DW5780B15	1" x 18" Cold Chisel 3/4" Hex x 21/32" Round Spline Shank Bulk	15
DW5783/5MP59	9-1/2" x 1-3/4" Bushing Tool Round Spline Shank	1
DW5783B10	9-1/2" x 1-3/4" Bushing Tool Round Spline Shank Bulk	10
DW5785/4LD27	Ground Rod Driver Spline Shank	1
DW5786B/1EC33	4" Clay Spade (Bulk)	1
DW5790/4LD28	Chuck Adaptor Spline Shank	1
DW5791/4LD29	Spline To SDS Adaptor	1
DW5792	Spline To A Taper Adaptor	1
DW5793	Spline To B Taper Adaptor	1
3/4" Hex Demo Steel		
DW5949/5MP73	Bushing Tool 9-1/2" x 1-3/4" Hex Demolition Hammer Steel	1
DW5949B10	Bushing Tool 9-1/2" x 1-3/4" Hex Demolition Hammer Steel (Bulk)	10
DW5950/4LD69	Bull Point 12" 3/4" Hex Demolition Hammer Steel	1
DW5950B15	Bull Point 12" 3/4" Hex Demolition Hammer Steel (Bulk)	15
DW5951/4LD70	Bull Point 20" 3/4" Hex Demolition Hammer Steel	1
DW5951B15	Bull Point 20" 3/4" Hex Demolition Hammer Steel (Bulk)	15
DW5952/4LD71	Scaling Chisel 3" x 12" 3/4" Hex Demolition Hammer Steel	1
DW5952B10	Scaling Chisel 3" x 12" 3/4" Hex Demolition Hammer Steel (Bulk)	10
DW5953/4LD72	Cold Chisel 1" x 12" 3/4" Hex Demolition Hammer Steel	1
DW5953B15	Cold Chisel 1" x 12" 3/4" Hex Demolition Hammer Steel (Bulk)	15
DW5954/4LD73	Cold Chisel 1" x 20" 3/4" Hex Demolition Hammer Steel	1

Cat #	Description	Qty
DW5954B15	Cold Chisel 1" x 20" 3/4" Hex Demolition Hammer Steel (Bulk)	15
DW5955	Bushing Head 1-3/4" x 1-3/4"	1
DW5958/4LD77	Ground Rod Drive 5/8,3/4 Rods 3/4" Hex Demolition Hammer Steel	1
DW5959B/1EC35	Clay Spade 4" x 17" 3/4" Hex Demolition Hammer Steel (Bulk)	1
1 1/8" Hex Demo Steel		
DW5960/4LD79	Bull Point 20" 1-1/8" Hex Demolition Hammer Steel	1
DW5961/4LD80	Sealing Chisel 3" x 20" 1-1/8" Hex Demolition Hammer Steel	1
DW5962/4LD81	Cold Chisel 20" 1-1/8" Hex Demolition Hammer Steel	1
DW5964/4LD83	Ground Rod Driver 1" Rod 1-1/8" Hex Demolition Hammer Steel	1
DW5965/4LD84	Clay Spade 5-1/2" x 20" 1-1/8" Hex Demolition Hammer Steel	1
2 PC Core Bits		
DW5900/4LD58	1-1/2" x 4" Core Bit Body	1
DW5901/4LD59	2" x 4" Core Bit Body	1
DW5902/4LD60	2-1/2" x 4" Core Bit Body	1
DW5903/4LD61	3" x 4" Core Bit Body	1
DW5904/4LD62	3-1/2" x 4" Core Bit Body	1
DW5905/4LD63	4" x 4" Core Bit Body	1
DW5906/4LD64	5" x 4" Core Bit Body	1
DW5907/4LD65	Centering Core Bit Body	1
DW5908/4LD68	Thread Adaptor	1
DW5909/4LD66	7" Spline Core Bit Shank	1
DW5910/4LD67	16" Spline Core Bit Shank	1
DW5911/4LT25	7" SDS Max Core Bit Shank	1
DW5912/1EZ68	16" SDS Max Core Bit Shank Adapter	1
1 PC Core Bits		
DW5914/3AB17	1-Piece 1-3/4" x 12" SDS Max Core Bit	1
DW5915/3AB18	1-Piece 1-3/4" x 22" SDS Max Core Bit	1
DW5916/3AB19	1-Piece 2" x 12" SDS Max Core Bit	1
DW5917/3AB20	1-Piece 2" x 22" SDS Max Core Bit	1
DW5918/3AB21	1-Piece 2-3/4" x 12" SDS Max Core Bit	1
DW5919/3AB22	1-Piece 2-3/4" x 22" SDS Max Core Bit	1
DW5920	1-Piece 3-1/4" x 12" SDS Max Core Bit	1
DW5921/3AB24	1-Piece 3-1/4" x 22" SDS Max Core Bit	1
DW5922/3AB25	1-Piece 3-1/2" x 12" SDS Max Core Bit	1
DW5923/3AB26	1-Piece 3-1/2" x 22" SDS Max Core Bit	1
DW5924/3AB27	1-Piece 4" x 12" SDS Max Core Bit	1
DW5925/3AB28	1-Piece 4" x 22" SDS Max Core Bit	1
DW5926/3AB29	1-Piece 5" x 22" SDS Max Core Bit	1
DW5927/3AB30	1-Piece 6" x 22" SDS Max Core Bit	1
DW5930/3AB31	1-Piece 1-3/4" x 12" Spline Core Bit	1
DW5931/3AB32	1-Piece 1-3/4" x 22" Spline Core Bit	1
DW5932/3AB33	1-Piece 2" x 12" Spline Core Bit	1
DW5933/3AB34	1-Piece 2" x 22" Spline Core Bit	1
DW5934/3AB35	1-Piece 2-3/4" x 12" Spline Core Bit	1
DW5935/3AB36	1-Piece 2-3/4" x 22" Spline Core Bit	1
DW5936/3AB37	1-Piece 3-1/4" x 12" Spline Core Bit	1
DW5937/3AB38	1-Piece 3-1/4" x 22" Spline Core Bit	1
DW5938/3AB39	1-Piece 3-1/2" x 12" Spline Core Bit	1
DW5939/3AB40	1-Piece 3-1/2" x 22" Spline Core Bit	1
DW5940/3AB41	1-Piece 4" x 12" Spline Core Bit	1
DW5941/3AB42	1-Piece 4" x 22" Spline Core Bit	1
DW5942	1-Piece 5" x 22" Spline Core Bit	1
DW5943	1-Piece 6" x 22" Spline Core Bit	1
DW5945/3AB45	Replacement Centering Bit	1

SDS ROTARY HAMMERS & DUST EXTRACTION SYSTEMS

CORDLESS SDS ROTARY HAMMERS

page 7

SPECIFICATIONS												
Manufacturer	DeWALT	DeWALT	Hilti®	Makita®	DeWALT	Hilti®	DeWALT	Hilti®	Hilti®	Bosch®	Bosch®	Makita®
Model #	DC2128/4YEC2	DC212KL/4LEX6	TE 4-A18	BHR240	DC223KA/1GEA5	TE 2-A	DC233KL/1PJK8	TE6-A Li	TE7-A	11536VSR	11536C-1	BHR261
Volts	18V	18V	18V	18V	24V	24V	36V	36V	36V	36V	36V	36V
Impact Energy (ft.-lbs.)	1.7	1.7	1.5	1.4	1.7	1.1	1.9	1.1	1.9	2.2	1.25	2.2
Active Vibration Control	SHOCKS®	SHOCKS®	No	No	SHOCKS®	No	SHOCKS®	No	No	No	No	No
RPM	0-1,100	0-1,100	0-1,090	0-1,100	0-1,100	0-900	0-1,150	0-900	0-740	0-960	0-1,500	0-1,200
BPM	0-4,100	0-4,100	0-5,200	0-4,000	0-4,100	0-4,410	0-4,400	0-5,000	0-4,000	0-4,260	0-4,800	0-4,800
Max Diameter	7/8"	7/8"	N/A	7/8"	7/8"	7/8"	1"	1"	1"	1"	3/4"	1"
Chipping	No	No	No	Yes	Yes	No	Yes	No	Yes	Yes	No	Yes
Weight	5.25 lbs.	6.7 lbs.	7.3 lbs.	7.0 lbs.	8.4 lbs.	8.3 lbs.	7.8 lbs.	8.4 lbs.	10.8 lbs.	9.6 lbs.	6.25 lbs.	9.9 lbs.
Length	10.5"	10.5"	12.75"	16.25"	10.5"	10.2"	10.5"	13.0"	14.0"	15.0"	12.25"	14.25"

D-HANDLE ROTARY HAMMERS

page 4, 5 & 6

SPECIFICATIONS						
Manufacturer	DeWALT	DeWALT	DeWALT	Bosch®	Bosch®	Makita®
Model #	D25023K/SLUP4	D25213K/1TDA1	D25223K/SLUP5	11224VSR	11255VSR	HR2475
Amps	6.9	8.0	8.0	6.9	7.2	7.0
Impact Energy	1.8	2.5	2.5	1.6	2.2	2.0
RPM	0-1,550	0-1,150	0-1,150	1,100	1,300	0-1,100
BPM	0-4,550	0-4,300	0-4,300	6,150	5,800	0-4,500
Active Vibration Control	No	No	SHOCKS®	No	No	No
Vibration Measurement	15.0 m/s ²	17.8 m/s ²	10.0 m/s ²	21.3 m/s ²	23.3 m/s ²	N/A
Chipping	Yes	Yes	Yes	Yes	Yes	Yes
Weight	5.5 lbs.	6.1 lbs.	7.1 lbs.	6.5 lbs.	6.7 lbs.	6.6 lbs.
Length	16.2"	16.6"	17.7"	17.5"	17.3"	16.75"

PISTOL GRIP HAMMERS

page 6

SPECIFICATIONS						
Manufacturer	DeWALT	DeWALT	Hilti®	Bosch®	Bosch®	Makita®
Model #	D25012K/SLUP3	D25113K/1TC28	TE 2	11250VSR	11253VSR	HR1830F
Amps	6.9	8.0	5.2	6.1	7.2	4.2
Impact Energy	1.8	2.5	1.8	1.6	2.2	1.2
RPM	0-4,150	0-1,150	0-930	0-1,000	0-1,300	0-1,500
BPM	0-1,550	0-4,300	0-4,600	0-4,600	0-5,800	0-5,000
Chipping	No	Yes	No	No	Yes	No
Weight	5.5 lbs.	5.7 lbs.	5.1 lbs.	5.4 lbs.	6.4 lbs.	3.7 lbs.
Length	13.2"	14.2"	13.5"	13.25"	14.8"	11.0"

L-SHAPE ROTARY HAMMERS

page 4, 5 & 6

SPECIFICATIONS								
Manufacturer	DeWALT	DeWALT	DeWALT	Hilti®	Hilti®	Bosch®	Makita®	Milwaukee®
Model #	D25313K/1TDA2	D25323K/SLUP6	D25324K/SLUP7	TE 6-S	TE 7-C	RH328VC	HR2811F	5363-21
Rated Size	1"	1"	1"	N/A	N/A	1-1/8"	1"	1"
Amps	8.0	8.0	8.0	5.2	6.0	8.0	6.3	7.0
Impact Energy	2.5	2.5	2.5	1.33	1.9	2.6	2.0	2.0
RPM	0-1,150	0-1,150	0-1,150	0-880	0-740	0-900	0-1,100	0-1,400
BPM	0-4,300	0-4,300	0-4,300	0-5,100	4,200	0-4,000	0-4,500	0-5,980
Active Vibration Control	No	SHOCKS®	SHOCKS®	No	No	Yes	Yes	No
Vibration Measurement	18.0 m/s ²	10.5 m/s ²	10.5 m/s ²	11.0 m/s ²	17.0 m/s ²	12.9 m/s ²	15.0 m/s ²	N/A
Chipping	Yes	Yes	Yes	No	Yes	Yes	Yes	Yes
Weight	6.5 lbs.	7.5 lbs.	7.8 lbs.	6.2 lbs.	7.0 lbs.	7.7 lbs.	7.3 lbs.	7.9 lbs.
Length	11.5"	12.4"	13.1"	12.6"	13.5"	13.2"	12.63"	12.25"
Removable Chuck	No	No	Yes	Yes	Yes	Optional	No	No

LARGE SDS ROTARY HAMMERS

page 6

SPECIFICATIONS				
Manufacturer	DeWALT	Hilti®	Bosch®	Makita®
Model #	D25404K/4YY97	TE 30/TE 30 C/AVR	RH432VC	HR3210
Rated Size	1-1/8"	N/A	1-1/4"	1-1/4"
Amps	8.3	7.7	8.5	8.2
Impact Energy	3.34	2.4	3.7	4.7
RPM	0-730	750	0-760	315-630
BPM	0-4,100	4,080	0-3,600	1,650-3,300
Active Vibration Control	No	Yes	Yes	Yes
Vibration Measurement	14.5 m/s ²	16.5/12 m/s ²	13.9 m/s ²	10.0 m/s ²
Chipping	Yes	No/Yes AVR	Yes	Yes
Weight	10.75 lbs.	8.8/9.2 lbs.	10.3 lbs.	10.6 lbs.
Length	15.25"	13.8/14.92"	15.75"	11.4"
Removable Chuck	Yes	Yes	No	No

SDS DUST EXTRACTION SYSTEMS

page 8

SPECIFICATIONS					
Manufacturer	DeWALT	DeWALT	DeWALT	DeWALT	Hilti®
Model #	D253020H/5YAV8	D253000H/1TA88	D253010/5YAV7	DC233KLH/5YAV9	TE 7-A Li w/TE DRS-M
Voltage	N/A	N/A	N/A	36V	36V
Built-in Motor	Yes	Yes	N/A	Yes	No
Shut-Off Delay	2 Second	2 Second	No	2 Second	No
HEPA Filtration	Yes	Yes	N/A	Yes	No
Separate Vac Required	No	No	N/A	No	No
Fits DeWALT SDS Hammers	Cordless 36V & 28V	Corded L-Shape	Corded & Cordless (except D25404)	N/A	N/A
Weight w/36V Hammer	-	12.4 lbs.	-	12.4 lbs.	13.4 lbs.
Kit Box	No	No	No	Yes	Yes








ROTARY HAMMER CROSS REFERENCE

SDS MAX & SPLINE COMBINATION ROTARY HAMMERS




SDS MAX: 1-9/16" - 1-1/2"

page 14

SPECIFICATIONS					
Manufacturer	DeWALT	Hilti®	Hilti®	Bosch®	Makita®
Model #	D25501K/SYAW0	TE 50	TE 60	11240	HR4002
Bit Style	SDS Max	SDS Max	SDS Max	SDS Max	SDS Max
Max Diameter	1-9/16"	N/A	N/A	1-9/16"	1-9/16"
Amps	12.0	8.75	10.0	10.0	10.0
Impact Energy (ft.-lbs.)	8.0	3.85	5.2	5.2	4.2
RPM	490	550	480	400	0-680
BPM	3,300	3,180	2,785	3,000	0-2,500
Electronics	No	Yes	No	No	Yes
2-Position Side Handle	Yes	No	No	No	No
Weight	13.55 lbs.	12.6 lbs.	13.9 lbs.	13.2 lbs.	13.7 lbs.








SPLINE: 1-9/16" - 1-1/2"

page 14

SPECIFICATIONS			
Manufacturer	DeWALT	Bosch®	Makita®
Model #	D25553K/SYAW1	11247	HR3851
Bit Style	Spline	Spline	Spline
Max Diameter	1-9/16"	1-9/16"	1-1/2"
Amps	12.0	10.0	10.0
Impact Energy (ft.-lbs.)	8.0	5.2	5.7
RPM	490	400	240
BPM	3,300	3,000	2,900
Electronics	No	No	No
2-Position Side Handle	Yes	No	No
Weight	14.0 lbs.	13.6 lbs.	16.5 lbs.




SDS MAX: 1-5/8" - 1-3/4"

page 12

SPECIFICATIONS							
Manufacturer	DeWALT	Hilti®	Bosch®	Bosch®	Makita®	Makita®	Milwaukee®
Model #	D25602K/SYAW3	TE 60-ATC-AVR	11264EVS	11263EVS	HR4010C	HR4510C	5426-21
Bit Style	SDS Max	SDS Max	SDS Max	SDS Max	SDS Max	SDS Max	SDS Max
Max Rec. Hole Capacity	1-3/4"	N/A	1-5/8"	1-3/4"	1-9/16"	1-3/4"	1-3/4"
Amps	13.5	10.0	13.0	13.5	11.0	13.5	14.0
Impact Energy	9.5	5.2	7.4	11.1	7.0	9.2	8.8
RPM	210-415	485-695	170-340	145-280	235-480	130-280	350-450
BPM	1,430-2,840	0-2,785	1,700-2,900	1,350-2,800	1,250-2,750	1,350-2,750	2,200-2,840
Active Vibration Control	SHOCKS®	Yes	Yes	No	Yes	Yes	Yes
Vibration Measurement	9.1 m/s ²	9.0 m/s ²	10.0 m/s ²	N/A	8.9 m/s ²	9.5 m/s ²	N/A
Torque Control	CTC	Yes	No	No	No	No	No
Electronics	Yes	Yes	Yes	Yes	Yes	Yes	Yes
2-Position Side Handle	Yes	No	No	No	No	No	No
Weight	15.1 lbs.	16.3 lbs.	15.1 lbs.	17.9 lbs.	13.9 lbs.	18.5 lbs.	14.8 lbs.










SPLINE: 1-5/8" - 1-3/4"

page 14

SPECIFICATIONS			
Manufacturer	DeWALT	Bosch®	Makita®
Model #	D25651K/SYAW4	11265EVS	HR4041
Bit Style	Spline	Spline	Spline
Max Rec. Hole Capacity	1-3/4"	1-5/8"	1-9/16"
Amps	13.5	13.0	12.0
Impact Energy	9.5	7.4	6.8
RPM	210-415	170-340	230-460
BPM	1,430-2,840	1,700-2,900	1,300-2,600
Active Vibration Control	SHOCKS®	Yes	No
Vibration Measurement	9.1 m/s ²	10.0 m/s ²	N/A
Torque Control	CTC	No	No
Electronics	Yes	Yes	Yes
2-Position Side Handle	Yes	No	No
Weight	15.5 lbs.	15.1 lbs.	13.7 lbs.

SDS MAX: 1-7/8" - 2"

page 13

SPECIFICATIONS									
Manufacturer	DeWALT	DeWALT	Hilti®	Hilti®	Bosch®	Makita®	Milwaukee®	Metabo®	Metabo®
Model #	D25712K/SYAW6	D25762K/SYAW7	TE 70-ATC	TE 80-ATC AVR	11245EVS	HR5210C	5342-21	KHE96	KHE76
Max Rec. Hole Capacity	1-7/8"	2"	N/A	N/A	2"	2"	2"	2"	2"
Amps	13.0	15.0	13.3	15.0	14.0	15.0	15.0	15.0	15.0
Impact Energy (ft.-lbs.)	11.7	15.0	8.15	8.5	13.5	14.75	19.9	19.9	11.8
RPM	137-275	125-250	360	360	120-250	130-260	125-250	125-250	0-300
BPM	1,260-2,520	1,150-2,304	2,760	2,760	1,100-2,500	1,350-2,750	975-1,950	0-1,950	0-2,735
Active Vibration Control	SHOCKS®	SHOCKS®	No	Yes	No	Yes	No	No	No
Vibration Measurement	7.8 m/s ²	9.3 m/s ²	22 m/s ²	8.8 m/s ²	N/A	17 m/s ²	N/A	N/A	N/A
Torque Control	CTC	CTC	Yes	Yes	No	No	No	No	No
2 Position Handle	Yes	Yes	No	No	No	No	No	No	No
Weight	17.5 lbs.	19.2 lbs.	19.6 lbs	22.6 lbs.	24.5 lbs.	25.6 lbs.	26.2 lbs.	28 lbs.	18.5 lbs.










Bosch® is a registered trademark of Robert Bosch GmbH. Makita is a registered trademark of Makita Corporation. Milwaukee® is a registered trademark of Milwaukee Electric Tool Corporation. Hilti® is a registered trademark of Hilti Aktiengesellschaft. Metabo is a registered trademark of Metabowerke GmbH, Germany. These trademarks are being used without permission of the trademark owners for comparison purposes only.

CHIPPING & DEMOLITION HAMMERS

SDS MAX CHIPPING




page 15

							
Manufacturer	DeWALT	DeWALT	Hilti®	Bosch®	Bosch®	Bosch®	Makita®
Model #	D25831K/SYAW2	D25881K/SYAW8	TE 500	11388	11321	11316EVS	HM1100C
Amps	13.5	15.0	9.2	10.0	13.0	14.0	11.0
Impact Energy (ft.-lbs.)	9.5	15.0	5.5	5.9	9.6	4.4-18.4	9.6
BPM	1,430-2,840	1,152-2,304	3,180	2,800	1,300-2,900	900-1,890	1,300-2,650
Active Vibration Control	SHOCKS®	SHOCKS®	No	No	Yes	No	No
Vibration Measurement	8.3 m/s ²	N/A	12.1 m/s ²	N/A	8.0 m/s ²	—	10 m/s ²
Variable Impact Control	7 Settings	8 Settings	2 Settings	No	Yes	Yes	Yes
Weight	13.6 lbs.	19.0 lbs.	11.0 lbs.	11.6 lbs.	12.8 lbs.	22.5 lbs.	13.5 lbs.
Length	18.5"	23"	18.5"	17.5"	18.6"	22.5"	20.6"







SPLINE/ROUND HEX CHIPPING

page 15

			
SPECIFICATIONS			
Manufacturer	DeWALT	Bosch®	Makita®
Model #	D25851K/SYAW5	11387	HM0810B
Amps	13.5	10.0	8.3
Impact Energy (ft.-lbs.)	9.5	5.9	7.6
BPM	1,430-2,840	2,800	2,900
Active Vibration Control	SHOCKS®	No	No
Vibration Measurement	8.3 m/s ²	N/A	15 m/s ²
Variable Impact Control	7 settings	No	No
Weight	14.0 lbs.	12.0 lbs.	11.7 lbs.
Length	18.6"	17.5"	16.65"

SDS MAX DEMOLITION






page 15

				
SPECIFICATIONS				
Manufacturer	DeWALT	DeWALT	Hilti®	Makita®
Model #	D25899K/2NER3	D25901K/2NER4	TE 706/TE 706 AVR	HM1214C
Amps	14.0	14.0	10.0	14.0
Impact Energy (ft.-lbs.)	18.5	18.5	7.4	19.0
BPM	1,020-2,040	1,020-2,040	2,760	950-1,900
Active Vibration Control	No	SHOCKS®	Yes	No
Vibration Measurement	11.5 m/s ²	8 m/s ²	9/5.5 m/s ²	N/A
Variable Impact Control	No	19 Settings	3 Settings	12 Settings
Weight	21.3 lbs.	22.8 lbs.	15.8/17.4 lbs.	27.0 lbs.
Length	25"	25"	22"	27.5"

3/4" HEX DEMOLITION




Hilti units have "proprietary steel"

page 15

					
SPECIFICATIONS					
Manufacturer	DeWALT	Hilti®	Hilti®	Bosch®	Makita®
Model #	D25941K/2NER5	TE 1000-AVR	TE 1500-AVR	11317EVS	HM1211B
Amps	15.0	15.0	15.0	12.8	10.0
Impact Energy (ft.-lbs.)	22.0	16.0	22.0	4.0-16.5	14.2
BPM	1,620	1,950	1,950	850-1,800	2,000
Active Vibration Control	SHOCKS®	Yes	Yes	No	No
Vibration Measurement	9 m/s ²	6.5 m/s ²	12 m/s ²	N/A	N/A
Weight	27.2 lbs.	26 lbs.	31.2 lbs.	22 lbs.	20.7 lbs.
Length	28.5"	27.5"	28.5"	22.0"	19.3"

PAVEMENT BREAKERS

page 16

			
SPECIFICATIONS			
Manufacturer	DeWALT	Bosch®	Makita®
Model #	D25909K/1TDAS	11304	HM1810
Amps	15.0	15.0	15.0
Impact Energy (ft.-lbs.)	61.0	43.0	46.0
BPM	900	1,400	1,100
Vibration	6.6 m/s ²	19 m/s ²	8 m/s ²
Versatile Hand Truck	Yes	No	No
Weight	68.3 lbs.	64.0 lbs.	70.6 lbs.
Service Warranty	2 Year	1 Year	1 Year



APPLICATION GUIDE

	4LEX6 DC212KL	1GEA5 DC223KA	1PJK8 DC233KL	5LUP3 D25012K	5LUP4 D25023K	1TCZ8 D25113K	1TDA1 D25213K	5LUP5 D25223K	1TDA2 D25313K	5LUP6 D25323K	5LUP7 D25324K	4YY97 D25404K	5YAW0 D25501K	5YAW1 D25553K	5YAW3 D25602K	5YAW4 D25651K	5YAW6 D25712K	5YAW7 D25762K
5/32"	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Red	Red	Red	Red	Red	Red	Red
3/16"	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Red	Red	Red	Red	Red	Red	Red
7/32"	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Red	Red	Red	Red	Red	Red	Red
1/4"	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Red	Red	Red	Red	Red	Red	Red
5/16"	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Red	Red	Red	Red	Red	Red	Red
3/8"	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Red	Red	Red	Red	Red	Red	Red
7/16"	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Red	Red
1/2"	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Red
9/16"	Yellow	Yellow	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green
5/8"	Yellow	Yellow	Yellow	Yellow	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green
3/4"	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Green	Green	Green	Green	Green	Green	Green
7/8"	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Green	Green	Green	Green	Green	Green	Green
1"	Red	Red	Yellow	Red	Red	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Yellow	Green	Green	Green	Green	Green	Green
1-1/8"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Green	Green	Green	Green	Green	Green
1-1/4"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Yellow	Yellow	Green	Green	Green	Green
1-3/8"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Yellow	Yellow	Green	Green	Green	Green
1-1/2"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Yellow	Yellow	Yellow	Yellow	Green	Green
1-9/16"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Yellow	Yellow	Yellow	Yellow	Green	Green
1-3/4"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Yellow	Yellow	Yellow	Yellow
2"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Yellow

HOLE SIZES

CORE DRILLING

<2-1/2"	Red	Red	Red	Red	Red	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green	Green
2-1/2" - 3-1/4"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Yellow	Green	Green	Green	Green	Green	Green
3-1/4" - 3-1/2"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Yellow	Yellow	Green	Green	Green	Green	Green
3-1/2" - 4"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Yellow	Yellow	Yellow	Yellow	Green	Green	Green
4" - 5"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Yellow	Yellow	Yellow	Yellow	Green
5" - 6"	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Red	Yellow	Yellow	Green

Optimum

Maximum

Not recommended

AVAILABLE THROUGH
GRAINGER[®]
FOR THE ONES WHO GET IT DONE

DEWALT[®]

SHOCKS **2**
ACTIVE VIBRATION CONTROL[®]
YEARS
FREE
SERVICE



Dealer Stamp:

dewalt.com
1-800-4 DEWALT

Copyright ©2010 DeWALT. The following are examples of trademarks for one or more DeWALT power tools and accessories: The yellow and black color scheme; the "D"-shaped air intake grill; the array of pyramids on the handgrip; the kit box configuration; and the array of lozenge-shaped humps on the surface of the tool.