

JOBBOX[®]

ON-SITE STORAGE



Unmatched Security, Versatility and Durability

Site-Vault[™] Security System

50% more locking points than competitive locking systems

PATENT PENDING

- 3-Point lock engagement is virtually impossible to bend or pry open



EZ-Loader[™] Skid Bolsters

Fork lift from any side

PATENT PENDING

- 7-Gauge, one-piece, steel bolster resists damage when dropped



PREMIUM STORAGE SOLUTIONS



CHESTS

Site-Vault™ Security System Patent pending



3-Point lock engagement

- Three locking points versus competitive locking systems that only feature two locking points
- Padlock is completely housed in a fully-welded 14 gauge steel casing making it nearly impossible to pry, cut or knock out in an attempted break-in
- Fluorescent orange tape indicates when the chest is unlocked, making it easy to check at night and from a distance

EZ-Loader™ Skid Bolsters Patent pending



Forklift from any side

- Easily load and unload heavy chests from trucks or warehouse
- Safely move loaded chests on site or to upper levels of buildings
- One piece skid bolster reinforces entire box bottom for heavier load capacity
- Uses 5/16" self-tapping screws for caster installation



HEAVILY REINFORCED LID

- Lid bolster resists bending from cargo placed on top of the box and from attempted break-ins



GRIP RITE™ CHANNELS

- Easy to grip the lid when wet or wearing gloves. Also provides lid reinforcement.



RECESSED HANDLES

- Extra tall and deep recess areas prevent pinched fingers and damage to the handle



STAKED AND WELDED HINGE

- Rugged 14-gauge steel, 3/8" continuous hinge with 1/4" steel pin and extra-large 1" knuckles. Staked and welded pin cannot be driven out. 3" horseshoe weld on both hinge ends.




PIANO LID BOXES

Site-Vault™ Security System

50% more locking points than competitive locking systems

- 3-Point lock engagement is virtually impossible to bend or pry open

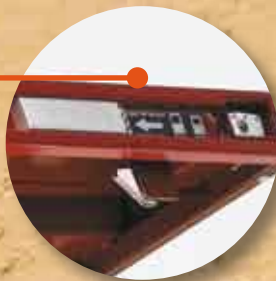

EZ-Loader™ Skid Bolsters

Fork lift from any side

- 7-Gauge, one-piece steel bolster resists damage when dropped



RECESSED HANDLES

- Extra tall and deep recess areas prevent pinched fingers and damage to the handle



2X THICKER SIDE WALLS

- Full pry bar and weather resistant design allows the lid to overlap side walls when closed
- Two deep side wall storage bins



TILT-N-STOW™ SHELF

- Bottom shelf lifts up and makes it easy to load and unload objects from the base



GAS SPRING LID LIFT GUARD

- Gas springs embedded in sidewall and guard design protect springs, strengthens sidewall and provides 17% more useable shelf space



Recessed Handles

Full-Length Lock Console with Three Locking Points

Formed Lid Sides Welded to Lid Bolster Resists Pry Bar Entry

Fully Staked and Welded Hinge with 3/8" Hinge, 1/4" Pin and 1" Knuckles

Recessed Handles

EZ-Loader™ Skid Bolster

Formed-In Reinforcements Strengthen Skid Bolsters

Door Opens a Full 90°

Site-Vault™ with Bolt Cutter Proof Lock Housing

Fully Welded Padlock Housing

Quick Release Gas Spring Removal

Built-In Storage Bins

Lower Front Panel to Reduce Lifting

Tilt-N-Stow™ Shelf

Uses 5/16" Self-Tapping Screws for Caster Installation

7-Gauge One-Piece Steel Bolster with Caster Holes

DROP-FRONT PIANO BOXES feature reinforced door for easy loading and unloading of heavy equipment. Available in 60" and 74" length models

HIGH-CAPACITY PIANO BOX features **75% more capacity than our popular model**

1-682990. Nearly 5' tall sidewalls organize more tools and equipment on the job site



Full-length stainless steel hinge resists corrosion

Pad-lockable drop down door prevents access to heavy tools and equipment while the piano box is open

Efficient tapered ramp design makes it easy to roll heavy objects into storage



Three 500 lb. Capacity, full width rear shelves

Six Built-In sidewall storage bins

Punched Holes for hanging safety harnesses

Tilt-N-Stow™ bottom shelf for easier access to base



FIELD OFFICE

One-Handle Lock Operation

Opens both bottom and top doors

- Handle slides down to release bottom doors and slides up to release top door



Steel Peg-Board and Deep Shelf

Bright White desktop for improved visibility

- Provides hanging storage and additional space for larger items



OFFICE CENTER WITH EXTRA LARGE DESKTOP

- Can be propped into a flat or slanted position and provides pad-lockable storage underneath



EZ-LOADER™ SKID BOLSTERS

- Fork lift from any side
- 7-Gauge, one-piece steel bolster resists damage when dropped



BOTTOM DOOR SHELVES

- Convenient for storing small parts and tools while reinforcing doors



30 CU. FT. SIDE STORAGE LOCKER

- Stores items up to 60" in length and is opened from a lanyard inside the lower cabinet for additional security





LID SAFETY PIN LATCH

- Pin secures open door support arm to bracket and sidewall for safety



FULL LENGTH HEAVY-DUTY LID AND DOOR HINGES


- Corrosion resistant, high-strength lid and door hinges provide enhanced durability and security



Site-Vault™ Security System

50% more locking points than competitive locking systems

- 3-Point lock engagement is virtually impossible to bend or pry open

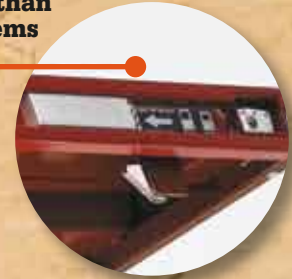

EZ-Loader™ Skid Bolsters

Fork lift from any side

- 7-Gauge, one-piece, steel bolster resists damage when dropped



Model #	Description	UPC	L	W	H	Usable Cu. Ft.	Shipping Cu. Ft.	Shipping Wt. (Lbs.)
Heavy-Duty Chests								
1-652990	36" Long Chest	0-43419-93110-7	36	20	23 3/4	8.3	10.0	98.0
1-653990	42" Long Chest	0-43419-93111-4	42	20	23 3/4	9.3	13.8	118.0
1-654990	48" Long Chest	0-43419-93112-1	48	24	27 3/4	15.4	22.3	148.0
1-655990	60" Long Chest	0-43419-93113-8	60	24	27 3/4	19.3	27.3	182.0
1-656990	48" Long Chest	0-43419-93114-5	48	30	33 3/8	24.3	33.3	190.0
1-658990	72" Long Chest	0-43419-93115-2	72	24	27 3/4	23.2	30.9	220.0

Model #	Description	UPC	L	W	H	Usable Cu. Ft.	Shipping Cu. Ft.	Shipping Wt. (Lbs.)
Piano Lid Boxes								
1-681990	Piano Lid	0-43419-93117-6	48	31	50	38.0	49.0	286.0
1-682990	Piano Lid	0-43419-93118-3	60	31	50	47.5	60.0	326.0
1-688990	Piano Lid	0-43419-93119-0	60	31	38	34.5	45.0	283.0
1-689990	Piano Lid	0-43419-93120-6	74	31	50	56.5	73.0	423.0
HIGH-CAPACITY PIANO LID BOX								
1-685990	High-Capacity Piano Lid	0-43419-93213-5	74.5	35.5	60.25	85.7	92.2	500.0
DROP FRONT PIANO LID BOX								
1-683990	60" Drop Front Piano Lid	0-43419-93151-0	60	30	50	47.5	60.0	405.0
1-684990	74" Drop Front Piano Lid	0-43419-93152-7	74	30	50	56.5	73.0	468.0

Model #	Description	UPC	L	W	H	Usable Cu. Ft.	Shipping Cu. Ft.	Shipping Wt. (Lbs.)
Field Office								
1-674990	Field Office	0-43419-93121-3	63	42	80	104.0	123.5	660.0

www.deltastorage.com

All information on this sheet is subject to change without notice.
For ordering, use Part# LIT136 © 2007 Delta Consolidated Industries, Inc.

Delta Consolidated Industries, Inc.
PO BOX 1846 Jonesboro, AR 72403-1846
800-643-0084 • Fax 870-935-4994