



Catalog Number	
Notes	Type

## FEATURES & SPECIFICATIONS

### INTENDED USE

Provides general illumination in residential and light commercial applications. Ideal for use in workshops, utility rooms and garages.

### ATTRIBUTES

Designed and manufactured to compliment a workshop's popular diamond plate storage cabinets. The rugged 20 gauge 5-3/8" diamond plate reflector directs bright light on work areas. Fully assembled, ready-to-install. Includes a 5' power cord and a pull chain power switch. The residential electronic ballast (120V 60Hz 0.99Amps) starts reliably down to 0°F.

Chain mount to ceiling using the 12" mounting chains included.

Utilizes (2) 32W linear T8 fluorescent lamps. (not included)

All mounting hardware is included.

For use on non-dimmable switches only.

### LISTING


CUL listed to US and Canadian safety standards and suitable for damp locations. Energy Star certified.

### WARRANTY

Guaranteed for two years against mechanical defects in manufacture.

# General Purpose Diamond Plate Shoplight


Linear T8 Fluorescent

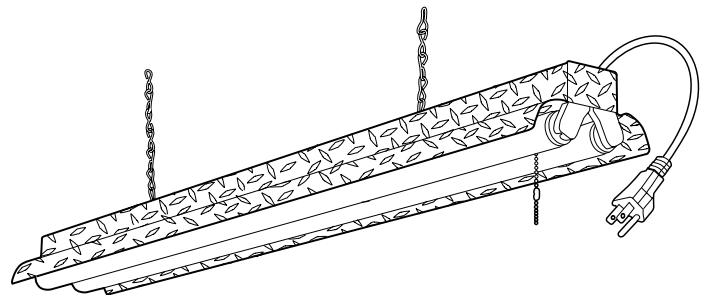

## DIMENSIONS

All dimensions are in inches (centimeters)

Nominal Size	Model No.	Number of Lamps	(A) Length Inches (cm)	(B) Width Inches (cm)	(C) Height Inches (cm)
4'	1241DP RE	2	48" (121.9)	5-2/8" (13.5)	2-1/2" (6.6)

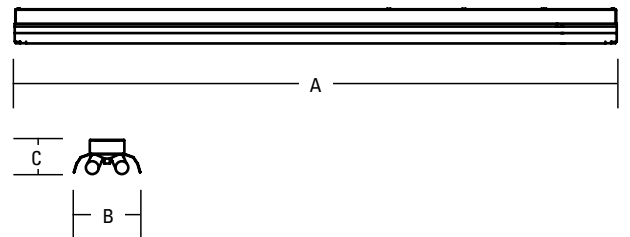

## ORDERING INFORMATION

Example: **1241DP RE**

Choose the boldface catalog nomenclature that best suits your needs and write it on the appropriate line. Order accessories as separate catalog numbers.

<b>1241DP</b>		<b>RE</b>		
Model Number		Ballast/Voltage		Options
<b>1241DP</b>	Requires (2) T8 fluorescent lamps (not included)	<b>RE</b>	120V Residential electronic ballast	(consult factory)

# Diamond Plate Shoplight Utility

---

## PHOTOMETRICS

Full photometric data report available within 2 weeks from request. Consult factory.

