

FEATURES & SPECIFICATIONS

INTENDED USE

White thermoplastic exit sign for general-purpose applications.

CONSTRUCTION

Injection-molded, flame-retardant, high-impact, thermoplastic housing with snap-fit design components for easy installation. Universal J-box pattern and universal mounting capabilities: top, back or end mounting (canopy included). Universal chevrons are easily removed for directional indication. Fully assembled single face with extra faceplate for easy field-conversion to double face.

Letters 6" high with 3/4" stroke, with 100 ft viewing distance rating, based upon UL924 standards.

OPTICS

The typical life of the exit LED lamp is 10 years.

ELECTRICAL

Dual-voltage input 120V or 277V AC. Emergency exits provided with test switch, status indicator and rechargeable battery. Maintenance-free ni-cad battery provides 90 minutes of emergency power.

LISTINGS

UL Listed. Meets UL 924, NFPA 101, NFPA 70-NEC and OSHA illumination standards. Indoor damp location 50°F to 104°F (10°C to 40°C) listed standard.

WARRANTY

Fixtures are covered by Lithonia Lighting 24-month warranty against mechanical defects in manufacture.

All life safety equipment, including emergency lighting for path of egress must be maintained, serviced, and tested in accordance with all National Fire Protection Association (NFPA) and local codes. Failure to perform the required maintenance, service, or testing could jeopardize the safety of occupants and will void all warranties.

Note: Specifications subject to change without notice.

Actual performance may differ as a result of end-user environment and application.

Catalog Number
Notes
Type

Contractor Select


Exits



EXG



EXR

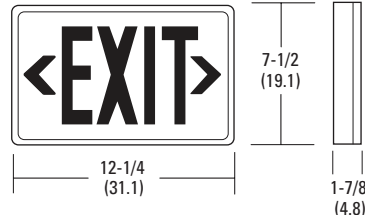

All dimensions are inches (centimeters).

ORDERING INFORMATION

Catalog Number	UPC	Description	Voltage	Wattage	Amps	Pallet Qty.	Standard Carton Qty.
EXR M6	745973431658	Red exit	120/277	3.8	.03/.02	270	6
EXG M6	745973431665	Green exit	120/277	3.8	.03/.02	270	6
EXR EL M6	745973431771	Red exit with backup battery	120/277	3.8	.03/.02	270	6
EXG EL M6	745973431788	Green exit with backup battery	120/277	3.8	.03/.02	270	6

Accessories¹: Order as separate catalog number.	
ELA WG1	Wireguard (back mount only)

Notes

1 See spec sheet [ELA-WG](#).

