

NEW

Milwaukee[®]

M18 FUEL[™]

DRIVEN TO OUTPERFORM.[™]



UP TO
2X
MORE
RUN-TIME

UP TO
30%
FASTER
CUTTING

UP TO
5X
LONGER
TOOL LIFE

SAWZALL[®]
Recip Saw Kit
22MH50

REDLITHIUM[™]
XC4.0




DRIVEN TO OUTPERFORM.™

M18 FUEL™ is engineered for the most demanding tradesmen in the world. Delivering unrivaled performance in a compact structure, all M18 FUEL™ products feature three Milwaukee®-exclusive innovations — the POWERSTATE™ Brushless Motor, REDLITHIUM™ Battery Pack and REDLINK PLUS™ Intelligence Hardware and Software — that deliver unmatched power, run-time and durability. Simply put, the M18 FUEL™ SAWZALL® reciprocating saw is the most powerful 18V cordless reciprocating saw on the market, the first to deliver true corded performance without the cord.

M18 FUEL


2 REDLINK PLUS™ INTELLIGENCE

- Most Advanced Electronic System on the Market for Maximum Performance
- Total System Communication with Overload Protection Increases Tool Life
- Built-in Fuel Gauge Displays Remaining Charge

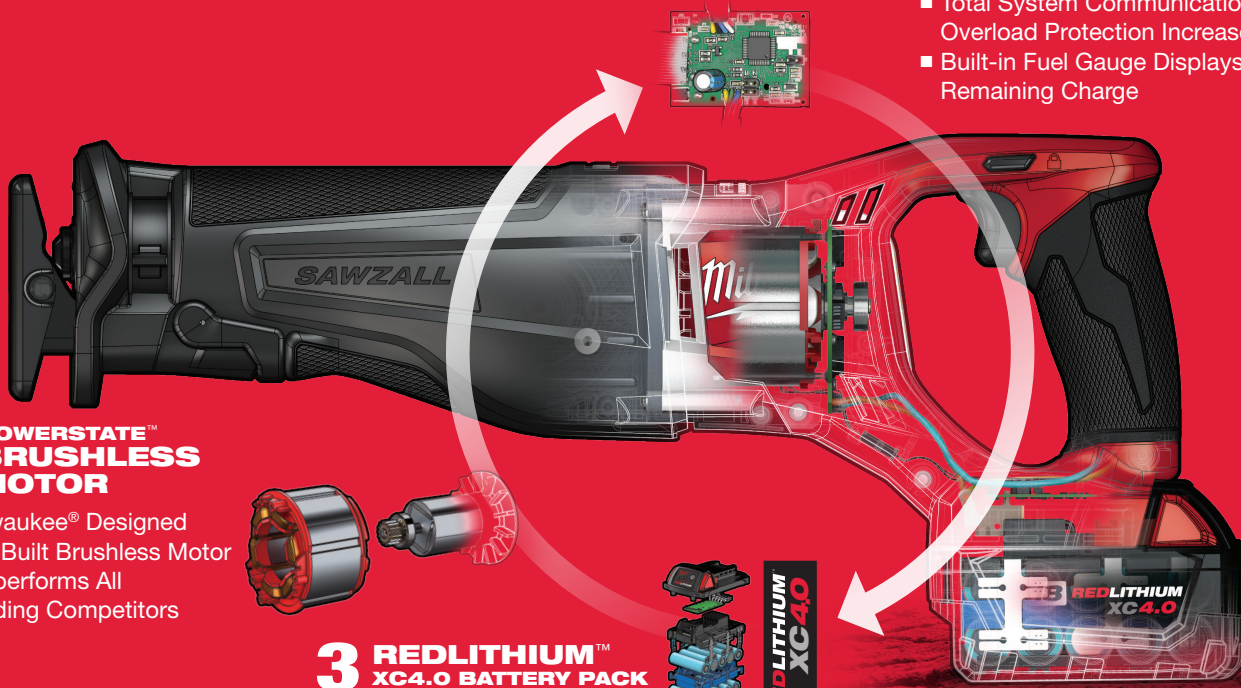

1 POWERSTATE™ BRUSHLESS MOTOR

- Milwaukee® Designed and Built Brushless Motor
- Outperforms All Leading Competitors

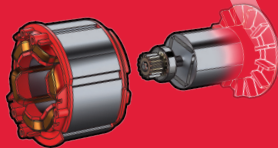

3 REDLITHIUM™ XC4.0 BATTERY PACK

- Up to 2X Run-Time
- 20% More Power
- Up to 2X More Recharges than Leading Competitor
- Operates Below -18° C / 0° F




UP TO
2X
MORE
RUN-TIME

UP TO
30%
FASTER
CUTTING


UP TO
5X
LONGER
TOOL LIFE

MORE RUN-TIME

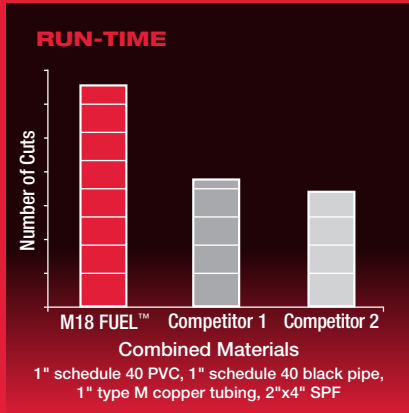


- REDLITHIUM™ XC4.0 Batteries deliver more work per charge than any competitive lithium-ion battery
- POWERSTATE™ Brushless Motor creates less friction and sparking, providing a more efficient use of battery power

FASTER CUTTING

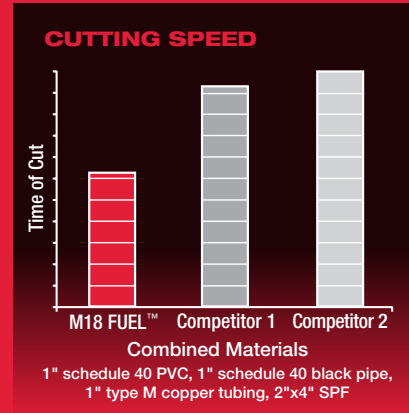


- Sustains torque and speed under load
- Reduced vibration provides faster starts in metal stock

LONGER TOOL LIFE

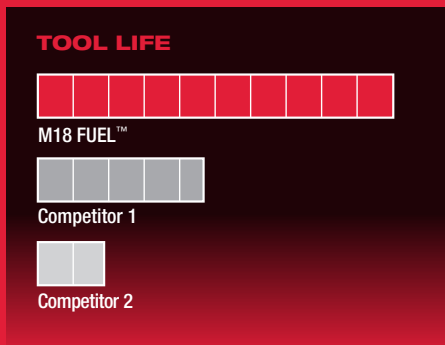

- Patented gear protecting clutch protects tool in abusive situation

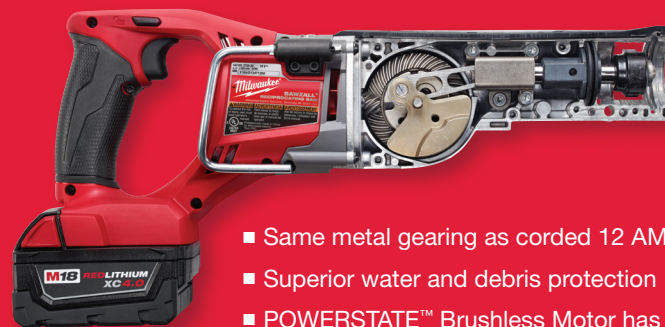

- Same metal gearing as corded 12 AMP SAWZALL®
- Superior water and debris protection
- POWERSTATE™ Brushless Motor has no wearable parts which allows the motor to run longer without needing service

SPECIFICATIONS AND MODELS

DESCRIPTION	SPECIFICATIONS	DESCRIPTION	SPECIFICATIONS
Stroke Length	1-1/8"	Hang Hook	Yes
SPM	0 – 3,000	LED Light	Yes
Adjustable Shoe	Yes	Length / Weight	18.5" / 8.9 lbs



M18 FUEL™ SAWZALL® Recip Saw (Tool-Only) 22MH49

Includes: 2720-20 M18 FUEL™ SAWZALL® Reciprocating Saw



M18 FUEL™ SAWZALL® Recip Saw (Kit - 1 Battery) 22MH50

Includes: 2720-20 M18 FUEL™ SAWZALL® Reciprocating Saw, (1) M18™ REDLITHIUM™ XC4.0 Extended Capacity Battery Pack, M12™ & M18™ Multi-Voltage Charger, Blade and Carrying Case



M18 FUEL™ SAWZALL® Recip Saw (Kit - 2 Batteries) 22MH51

Includes: 2720-20 M18 FUEL™ SAWZALL® Reciprocating Saw, (2) M18™ REDLITHIUM™ XC4.0 Extended Capacity Battery Packs, M12™ & M18™ Multi-Voltage Charger, Blade and Carrying Case





FUEL

FUEL

FUEL

FUEL

FUEL

FUEL

FUEL



REDLITHIUM
2.0/XC4.0



**FASTEST GROWING 18V
SYSTEM ON THE MARKET**
50+ TOOLS



M18

