



# WORKSTAR

Rechargeable, LED Work Light

	Model No. 511510	Model No. 511500
<b>LUMENS</b>	900 high 450 low	2,200 high 1,000 low
<b>LIGHTING RANGE</b>	50 ft.	65 ft.
<b>BUILD TYPE</b>	LED	LED
<b>LAMP LIFE</b>	50,000	50,000
<b>KELVIN</b>	5,000	5,000
<b>WATTAGE</b>	10	20
<b>WEIGHT</b>	2.2 lbs.	3.4 lbs.
<b>TEMP RATED</b>	-4°F - 140°F	-4°F - 140°F
<b>BATTERY TYPE</b>	3.7V 6000mah Li-Ion	7.4V 4.5ah Li-Ion
<b>RUN TIME</b>	4 hours high 8 hours low	3 hours high 7 hours low
<b>IP RATING</b>	IP65	IP65




Mini WorkStar LED Flood Light  
Model No. 511510

- > 4 hr. recharge time
- > Mount to tripod or magnetic base
- > Water & shock resistant
- > 120° beam spread
- > Includes wall charger

Option:  
Magnetic Mount  
Model No. 511520

WorkStar LED Flood Light  
Model No. 511500

- > 4 hr. recharge time
- > Mount to tripod or magnetic base
- > Water & shock resistant
- > USB charging port on back
- > Includes car and wall chargers
- > 30° beam spread

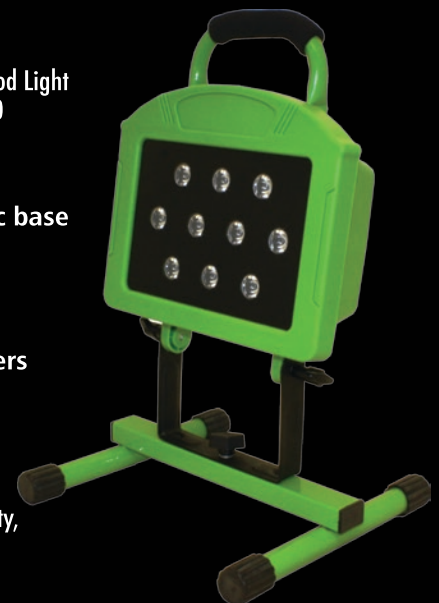

**TARGET APPLICATIONS**

Industrial/MRO, Construction, Rail, Utility, Public Works, Law Enforcement, Fire