


PRODUCT SPECIFICATIONS

# 1x4 Flatlight™ Luminaire Fixture

Replaces existing fluorescent 1x4 Luminaires

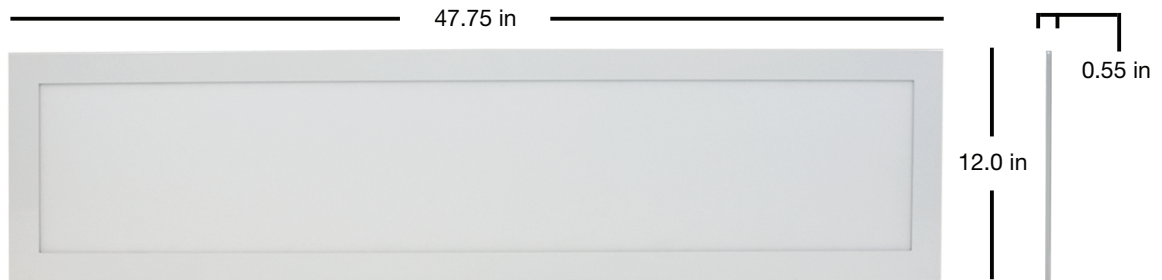


### ADVANTAGES

- Internal driver allows for TruFlat™ Mounting
- Edge-lit LED provides a thin energy efficient light source with excellent uniformity
- 90° bezel edge
- Lasts 60%\* longer than standard troffer lighting
- Bright uniform light
- Low heat dissipation - reduce HVAC costs
- Low energy consumption
- Replaces fluorescent fixture and tube
- Environmentally positive - RoHS compliant
- Type IC Rated
- 5 year limited warranty

### APPLICATIONS

Suitable for dry and damp locations

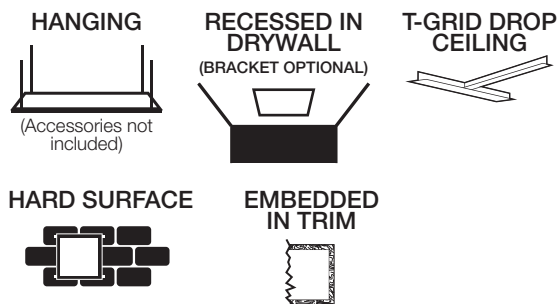

### SPECIFICATIONS

|                       |                    |
|-----------------------|--------------------|
| Model Number          | FLT14C40MDUP44-A   |
| Power                 | 48W                |
| AC Voltage, Frequency | 110~300V, 50/60 Hz |
| Color Temp (nom.)     | 4000K              |
| Operation Temp        | - 20°C ~ 40°C      |
| CRI                   | ≥80                |
| Lumen Output (min.)   | 4500 lm            |
| Dimming               | No                 |
| Lifetime Rating       | 50,000 Hrs         |

### PACKAGING

|                            |                        |
|----------------------------|------------------------|
| Weight (±0.5 lb)           | 10.2 lbs               |
| Mounting plate             | 2.0 lbs                |
| Size (L x W x H) (±0.1 in) | 47.75 x 12.0 x 0.55 in |
| Box Dimensions             | 51.75 x 15.5 x 2.6 in  |
| Gross Weight               | 14.6 lbs               |
| UPC                        | 8 55158 00316 4        |




### INCLUDED IN BOX

- Mounting plate
- Installation guide
- Installation bracket
- Wire Nuts (3)
- Dry wall screws (4)
- Toggle bolts (4)
- Grounding wire

\*Based on standard ballast average lifetime.

**Polar Candela Distribution**

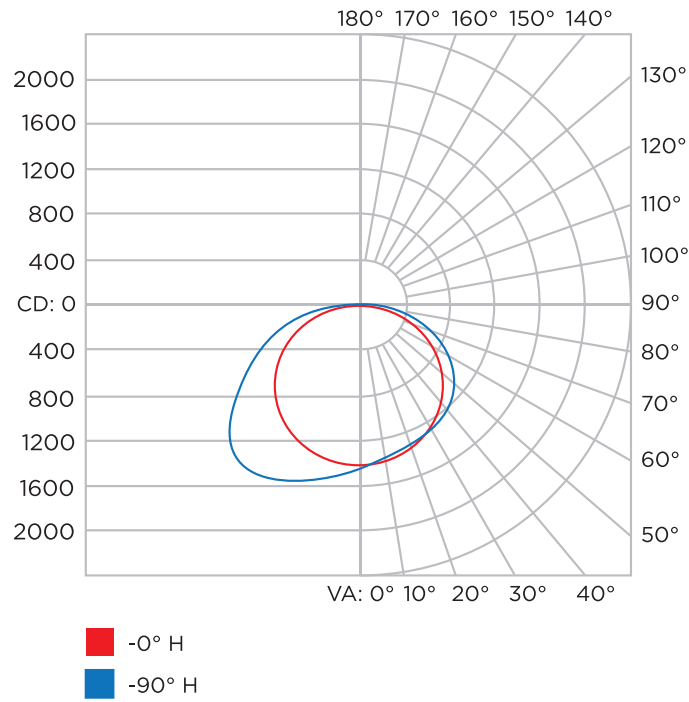

\*Based on standard ballast average lifetime.