


PRODUCT SPECIFICATIONS

# 1x1 Beveled Edge Flatlight™ Luminaire Fixture

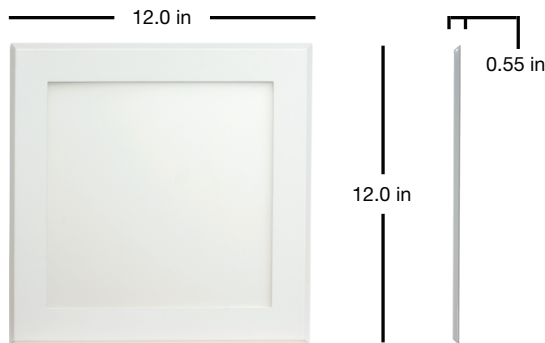

SPECIFICATIONS	
Model Number	FLT11R27MD0811-A
Power	10W
AC Voltage, Frequency	90~130V, 50/60 Hz
Color Temp (nom.)	2700K
Operation Temp	- 20°C ~ 40°C
CRI	≥ 80
Lumen Output (min.)	900 lm
Dimming	Yes*
Lifetime Rating	50,000 Hrs

**ADVANTAGES**

- Internal driver allows for TruFlat™ Mounting
- Edge-lit LED provides a thin energy efficient light source with excellent uniformity
- 30° bezel edge design for a sleek look
- Uses about 80%\*\* less energy than standard household light fixtures
- Low heat dissipation - reduce HVAC costs
- Low energy consumption
- Replaces current household lights
- Environmentally positive - RoHS compliant
- 5 year limited warranty

PACKAGING	
Weight (Flatlight) (±0.5 lb)	2.89 lbs
Mounting plate	0.4 lb
Size (L x W x H) (±0.1 in)	12.0 x 12.0 x 0.55 in
Box Dimensions	14.0 x 14.5 x 2.6 in
Gross Weight (±0.5 lb)	4.2 lbs
UPC	8 55158 00313 3

**APPLICATIONS**

Suitable for dry and damp locations

**HARD SURFACE**



**HANGING**



**EMBEDDED IN TRIM**




**INCLUDED IN BOX**

- Mounting plate
- Installation guide
- Installation bracket
- Two-wire connector
- Grounding wire
- Wire Nuts (3)
- Junction box screws (2)
- Dry wall screws (4)
- Toggle bolts (4)

\*With select dimming controls  
 \*\*Compared with incandescent lighting

### Polar Candela Distribution

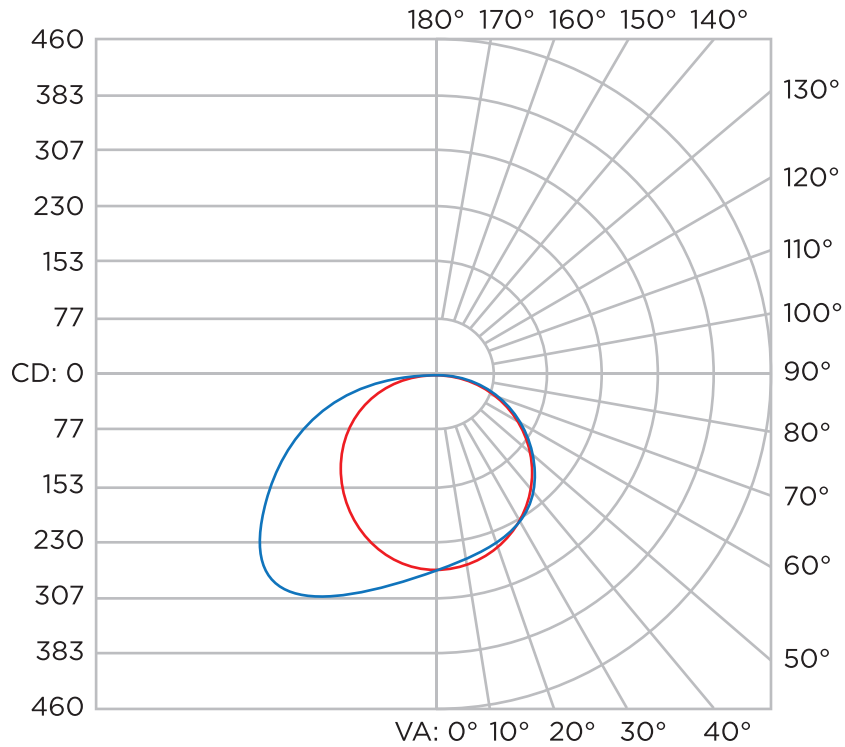

- -0° H
- -90° H

### Illuminance at a Distance

	Center Beam LUX	Beam Width	
2.0m	67.25 LUX	4.8m	7.0m
4.0m	16.81 LUX	9.6m	14.0m
6.0m	7.47 LUX	14.4m	20.9m
8.0m	4.20 LUX	19.2m	27.9m
10.0m	2.69 LUX	24.0m	34.9m
12.0m	1.87 LUX	28.8m	41.9m

- Vert. Spread: 100.4°
- Horiz. Spread: 120.4°