

PRODUCT SPECIFICATIONS

1x2 Beveled Edge Flatlight™ Luminaire Fixture



ADVANTAGES

- Internal driver allows for TruFlat™ Mounting
- Edge-lit LED provides a thin energy efficient light source with excellent uniformity
- 30° bezel edge design for a sleek look
- Uses about 80%** less energy than standard household light fixtures
- Low heat dissipation - reduce HVAC costs
- Low energy consumption
- Replaces current household lights
- Environmentally positive - RoHS compliant
- 5 year limited warranty

APPLICATIONS

Suitable for dry and damp locations

HARD SURFACE



HANGING



(Accessories not included)

EMBEDDED IN TRIM



SPECIFICATIONS

Model Number	FLT12R27MD1622-A
Power	23.5W
AC Voltage, Frequency	90~130V, 50/60 Hz
Color Temp (nom.)	2700K
Operation Temp	- 20°C ~ 40°C
CRI	≥80
Lumen Output (min.)	2000 lm
Dimming	Yes*
Lifetime Rating	50,000 Hrs

PACKAGING


Weight (Flatlight) (±0.5 lb)	5.0 lbs
Weight (Mount)	0.4 lb
Size (L x W x H) (±0.1 in)	12.0 x 24.0 x 0.55 in
Box Dimensions	14.2 x 26.3 x 2.6 in
Gross Weight	7.0 lbs
UPC	8 55158 00314 0

INCLUDED IN BOX

- Mounting plate
- Installation guide
- Two-wire connector
- Installation bracket
- Wire Nuts (3)
- Dry wall screws (4)
- Toggle bolts (4)
- Grounding wire

*With select dimming controls **Compared with incandescent lighting

Polar Candela Distribution

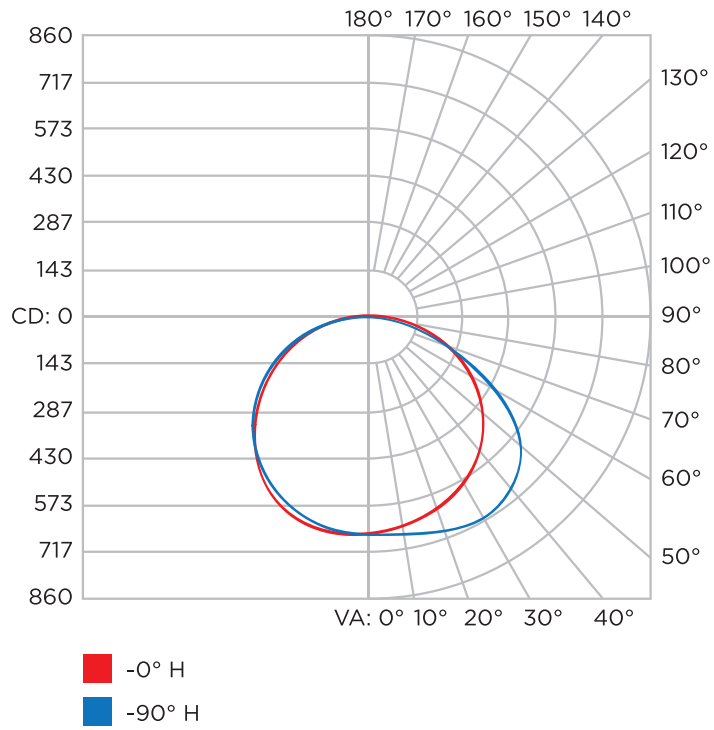

Illuminance at a Distance

