

ICON™ Be Seen... Be Safe... Be Cool...



The Icon for premium breathable, high visibility outerwear.

The Icon™ Premium ANSI Compliant Breathable And High Visibility Outerwear - Polyurethane On 300 Denier Polyester

Engineered to provide superior comfort and safety in the toughest work environments.

- ANSI/ISEA 107 Class 3 compliant suit, jacket, and coat for high visibility and breathability.
- Loaded with premium features for multipurpose applications.
- Fluorescent background colors for excellent daytime visibility.
- 2" silver reflective tape reflects light for 360° nighttime conspicuity.
- Icon 3.1™ jacket system (style J24172) comes standard with removable fleece jacket for all season comfort and use.


Ideal Applications: For use in environments where high visibility and breathability are desired for wearer safety and comfort.



Zipper/storm fly front with throat guard. D-ring access for fall protection harness. Roll-a-way, adjustable hood in collar, and mesh/taffeta lining.



Removable 300g fleece jacket available in Icon 3.1 style J24172 or as a stand alone jacket style J72003.

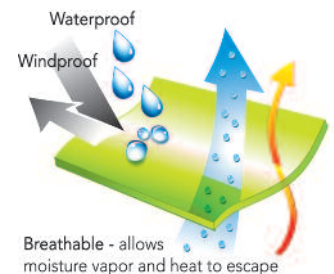

FEATURES & BENEFITS

	ICON	ICON 3.1
Waterproof, breathable fabric for all season comfort	X	X
Overhead shoulder design for complete freedom of movement	X	X
Stitched and taped sealed seams for 100% waterproof protection	X	X
Zipper/storm fly front with throat guard, seals out wind and rain	X	X
Roll-a-way adjustable hood in collar design for added convenience	X	X
Full-vented cape back for improved air circulation	X	X
D-ring access for fall protection harness	X	X
Mesh/taffeta lining for added comfort	X	X
Hand warmer side pockets with front cargo pockets and hook and loop closure	X	X
Convenient front radio pocket with exterior badge holder	X	X
Inner breast pocket with zipper closure	X	X
Elastic cuffs with hook and loop take-up straps on sleeves	X	X
Tapered sweep with adjustable elastic drawcord on jacket for added protection	X	X
2 Mic Tabs	X	X
Heavy duty suspenders with quick release buckles and crossover	X	X
Hook and loop take-up straps on leg cuffs	X	X
Take-up snaps on overall waist for adjustable fit	X	X
Icon jackets have inner attachment system to accommodate Phase 3™ (J25022) or black fleece jacket (J72003) as a liner	X	

FLEECE JACKET/ICON 3.1 LINER

300 gram insulating black fleece jacket can be zipped in and out of Icon	X
Fleece jacket has 2 slash pockets with zippers and adjustable elastic drawcord	X

Icon™, Icon 3.1™, Phase 3™, and Job Sight™ are trademarks of Tingley Rubber Corp.

#4084 2/13



ICON – 5.5 Oz. Mat'l Wt. – 12 Mil Thick

JACKETS

J24122	Fluorescent Yellow-Green-Black - Attached Hood - Silver Reflective Tape	S – 5XL
J24129	Fluorescent Orange-Red-Black - Attached Hood - Silver Reflective Tape	S – 5XL

OVERALLS

O24122	Fluorescent Yellow-Green - Snap Fly Front - Silver Reflective Tape	S – 5XL
O24129	Fluorescent Orange-Red - Snap Fly Front - Silver Reflective Tape	S – 5XL

COAT

C24122	Fluorescent Yellow-Green - 48" - Attached Hood - Silver Reflective Tape	M–5XL
--------	---	-------

ICON 3.1 – 5.5 Oz. Mat'l Wt. – 12 Mil Thick Shell – 300g Fleece Jacket

JACKET SYSTEM

J24172	Fluorescent Yellow-Green-Black - Attached Hood - Silver Reflective Tape Removable Black Fleece Jacket	S – 5XL
J72003	Black Fleece Jacket - Replacement Liner	S – 5XL

